


Tool Registration / Download eWarranty (<https://www.bosch-pt.co.in/in/en/service/warranty/beconnected/>)
Sustainability (<https://www.bosch-pt.com/ww/gb/en/company/sustainability/>)
Contact (<https://www.bosch-pt.co.in/in/en/service/after-sales-service/contact/>)

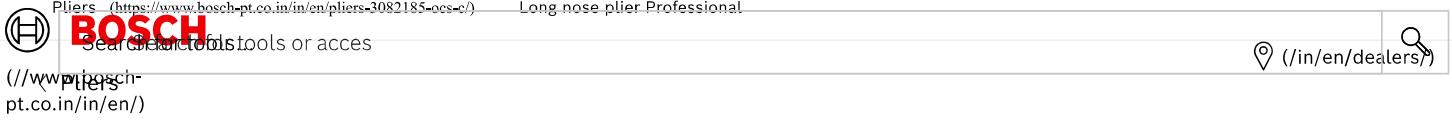

LONG NOSE PLIER PROFESSIONAL

Pliers

Order number 1.600.A01.TH8



- The high-strength chrome vanadium steel shanks and specially hardened cutting edges are tough and durable
- Less effort is required for cutting than with standard pliers thanks to the optimised high-leverage design
- The soft rubber grip and anti-slip edges ensure comfortable and safe use, especially one-handed

Select a variant
Long nose plier

YOUR SELECTED VARIANT



YOUR SELECTED VARIANT

📍 Find a local dealer
LONG NOSE PLIER PROFESSIONAL

1 600 A01 TH8

LONG NOSE PLIER PROFESSIONAL
📍 Find a local dealer
✓ YOUR SELECTION

Order number: 1 600 A01 TH8

📍 Find a local dealer
Included in this variant

+ Hang Tag

Your selection <https://www.bosch-pt.co.in/in/en/products/long-nose-plier-1600A01TH8#>

TECHNICAL DATA

Additional data

Pliers type	Long Nose Plier
One-hand usage	✓
Anti-slip shoulders	✓
Cutting diameter soft	4 mm
Weight	0.201 kg
Diameter (max.)	4 mm
Hardened cutting edges	✓
High leverage design	✓
Cutting diameter hard	2 mm
YOUR SELECTED VARIANT Material	Chrome Vanadium



YOUR SELECTED VARIANT

Soft grip

LONG NOSE PLIER PROFESSIONAL

1 600 A01 TH8

Cutting diameter high hardness

1.6 mm

Cutting diameter medium-hard

2.8 mm

Find a local dealer

* You can find more information about the deviations in the following link: Technical features of products

LONG NOSE PLIER PROFESSIONAL: FURTHER INFORMATION

Product Highlights

The Bosch Professional long nose pliers are made from high-strength chrome vanadium steel with specially hardened cutting edges for an extended lifespan. The optimised high-leverage design takes up to 30% less effort when cutting than standard pliers, and the soft rubber grip and anti-slip edges make the pliers comfortable and safe to use, especially one-handed

Additional Information

The maximum cutting diameter for soft wires (220 N/mm²) is 4.0 mm, for hard wires (2030 N/mm²) 1.6 mm

NEED A SPARE PART?

Here you will find the right spare parts for your professional Bosch tool quickly and easily.

Our products
below may
tool, please



Find a spare part

Part number
1600A016L

Product name
Long nose

Description
Pliers



DOWNLOADS

PRODUCT DATA SHEET

Product data sheet | Long nose plier (PDF 1.5 MB)

CUSTOMER CONTACT CENTER

YOUR SELECTED VARIANT



 Phone number:
0 1800 425 8665

YOUR SELECTED VARIANT
Have any questions about our products or service?

LONG NOSE PLIER PROFESSIONAL

Bosch Power Tools,
1600 A01 TH8
Post Box No. 3000, Hosur Road, Adugodi, Bangalore- 560030 Karnataka

Monday – Saturday:

 Find a local dealer

8 a.m - 8 p.m.

bpt@in.bosch.com (mailto:bpt@in.bosch.com)

FAQ

 Frequently asked questions specifically about our repair, pickup and spare parts service

Learn more [\(//www.bosch-pt.co.in/in/en/service/after-sales-service/faq/\)](http://www.bosch-pt.co.in/in/en/service/after-sales-service/faq/)

Power Tools



Measuring Tools



Accessories



Further Innovations



About Bosch



Help Center



Follow us on



© Bosch Limited 2021, all rights reserved

[Imprint](#)

[Data Protection Notice](#)

[Accessibility](#)

[About Bosch](#)

[Sustainability](#)

[Career](#)

[Press](#)

[Product Security \(PSIRT\)](#)

[Privacy settings](#)

[Report a Vulnerability](#)

© Bosch Limited 2021, all rights reserved

YOUR SELECTED VARIANT