


METAL SAFETY QUICK COUPLINGS - CSM 11

Parallel female thread coupler

Profile : ISO 6150C



Part number	Female thread	Min. operating pressure (bar)	Flow rate at 6.00 bar (l/min) ($\Delta P = 0.60$ bar)	ID passage (mm)	Temperature min/max (°C)
CSM 111103	G1/2	2.00 / 16.00	4120.00	11 mm	-15.00 / 70.00
CSM 111104	G3/4	2.00 / 16.00	4120.00	11 mm	-15.00 / 70.00

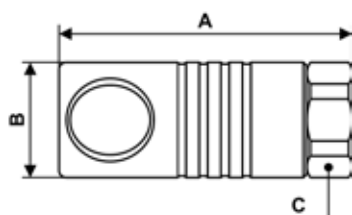

Part number	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)
CSM 111103	87.00	33.00	30.00
CSM 111104	92.00	33.00	30.00