

Features

- Crocodile Clips
- Can be attached by crimp or screw connection
- Jaw open 0.625" (16mm) max
- Contact Material: Copper
- Length: 2.44" (61.91mm)
- Rating: 40 Amps

RS PRO Crocodile Clips, Copper Contact, 40A

RS Stock No.: 0205407



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- This general purpose alligator clips are suitable for a wide variety of applications, durable and hard wearing with screw and crimp terminations.
- This Electric Heavy Duty, General Purpose, Crocodile and Alligator Clips
- A concise offering of steel and copper alligator and crocodile clips from RS suitable for applications including grounding clips, test meters clips, battery terminal connection and many others that require a durable and hardwearing alligator or crocodile clip

General Specifications

Contact Material	Copper
Product Name	Crocodile Clips
Type	General Purpose Clip
Insulated	No
Connection Type	Can be attached by crimp or screw connection

Commented [波辛1]:

Electrical Specifications

Current rating	40A
----------------	-----

Mechanical Specifications

Jaw Opening ($\pm 10\%$)	0.625" (16 mm) max
Contact Material	Copper
Insulation Material	No
Dimensions ($\pm 10\%$)	Overall length 2.44"(61.91mm), overall width 0.5"(12.7mm), overall height 0.69" (17.46mm)


Approvals

Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

Spec Drawings Diameter

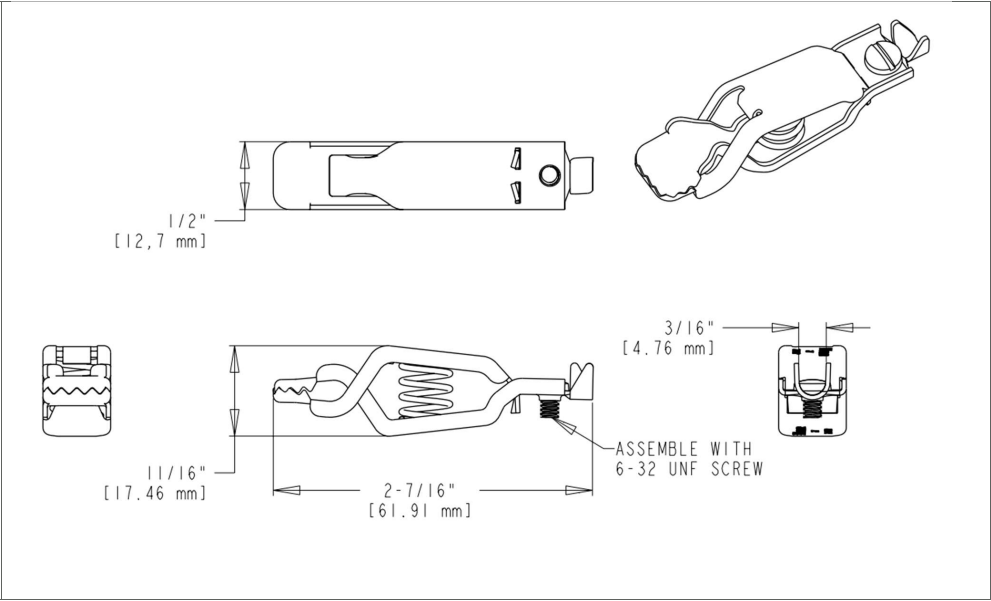

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION