


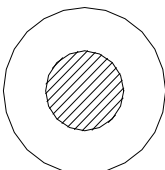

Datasheet

Product Name:	MIL-W-22759/11 28AWG
Product Discription:	MIL-W-22759/11 28AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		600V			Conductor		Stranded Sliver plated copper					
Rated Temperature:		200℃			Size(AWG)		28					
Reference Standard:		MIL-W-22759/11			Construction(±0.008mm)		7/0.127					
Cross Section					Stranded Dia.(mm)Ref.		0.38					
					Insulation Material		PTFE					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.25					
					Insulation Dia.(±0.08mm)		0.89					
Marking					Remark:							
No marking on the cable jacket					8776187 Red		8776178 Blue					
					8776171 Black		8776180 White					
					8776174 Brown							
Applications					Characteristics				Customer Approve			
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.					Test Item			Standard Value			Seal & Stamp	
					Test Material			PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m			1000				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			VW-1				
Revisions					Max.DC Resistance(20℃ Ω/km)			208.66(MAX)				
Version	Description		Drawn by	Approved by	Date							
0	New document issue		Danniel	Jason	19/05/2015							

Seal & Stamp

Signature:

Date: