



Brand of NTN corporation

Technical data

UKFC209H

Bearing units




Grey cast housing, radial insert ball bearing with adapter sleeve, seal with slinger

KIT CONTENT

UK209G2H, FC209

VISUAL (S)

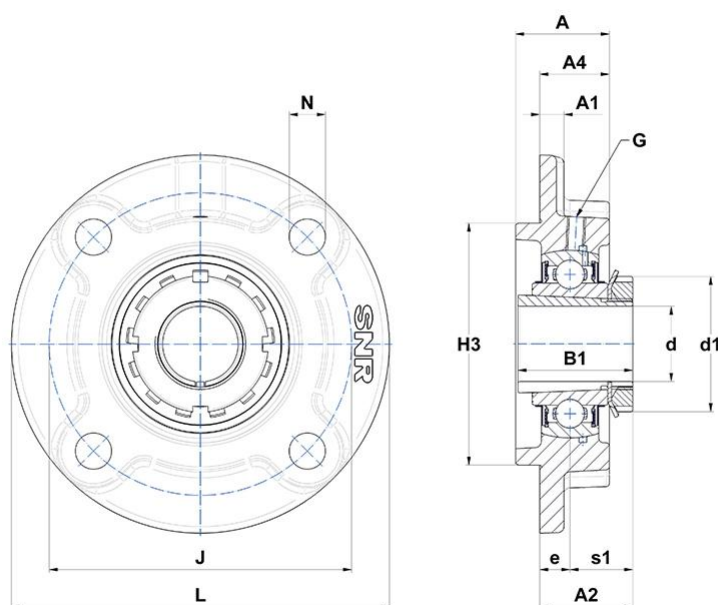

PRODUCT DEFINITION

Brand	SNR
A - Housing height	38 mm
A1 - Housing foot height / flange height	10 mm
A2 - Total height from mounting surface	36 mm
A4 - Housing height from mounting surface	26 mm
B - Width of Inner Ring	30 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

B1 - Overall width Inner Ring	50 mm
d - Shaft diameter	40 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	65 mm
e - Distance mounting surface to bearing center	10 mm
G - Grease fitting	M6x1
H3 - Centering dia	105 mm
J - Mounting holes distance	132 mm
L - Housing width / diameter	160 mm
N - Mounting hole dimension	16 mm
s1 - Distance nut to middle of bearing raceway	26 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	31850000 mN
C0 - Static load rating	20800000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	2,55 kg
Adapter sleeve designation	H2309

