


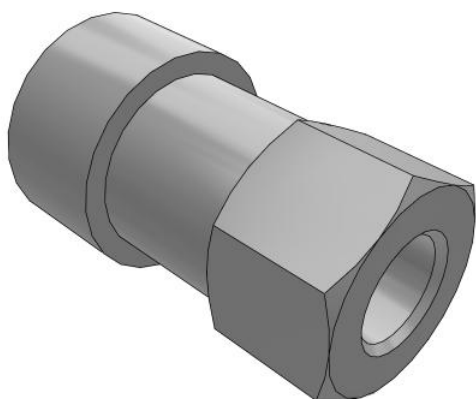

KK130S-*F, S-Couplers, Female Thread

KK130S-02F

Datasheet


General series information

- Female Thread.
- Applicable Port Size: Rc1/8, Rc1/4, Rc3/8, Rc1/2, NPT1/8, NPT1/4, NPT3/8, NPT1/2.

Standard specifications

Type	S (Socket)
Piping Port Size	Rc 1/4
Pressure medium	Air
Maximum operating pressure	1.5 MPa
Minimum operating pressure	0 MPa
Proof pressure	2 MPa
Maximum ambient temperature	80 °C
Minimum ambient temperature	-20 °C (No freezing)
Sealing principle	Male thread with sealant
Non-greased specification	Sleeve: Electroless nickel plated Other external metal parts: Zinc chromated
Weight	0.092 Kg

Dimensions

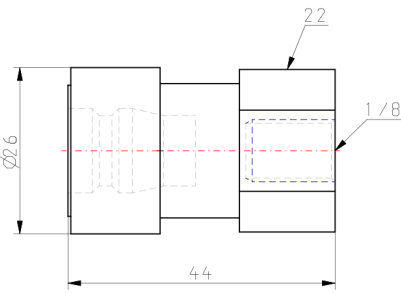

Additional information

Catalogue

[KK130-B_EU.pdf](#)