

SylCircle SYLCIRCLE 17W 3000K 0043282



Product features

- Ceiling / wall luminaire with integrated LED Perfect solution for hallways, circulation spaces or foyer. Even and uniform light distribution with a halo lighting effect on the wall surface 17W 1500 lumens Supplied with LED driver (non-dimmable) IK03 PMMA diffuser Low maintenance with 30,000 hours LED life expectancy



PRODUCT OVERVIEW

IPC Code	0043282
Product name	SYLCIRCLE 17W 3000K
Technology	LED
Housing	Aluminium
Mount	Ceiling surface mounting
Environment	Internal
General application	Residential & Consumer
Certifications	EUNEW009
ETIM Class	EC002892
E-number FI	4170512
E-number SE	7503209
Fixture luminous flux (lm)	1500
Luminaire efficacy (lm/W)	88
Colour temperature (K)	3000
Light colour	Warm White
CRI (Ra)	80
Colour Variation Initial (SDCM)	6
Beam Angle (°)	120
Glare control	< 28
Photobiological Risk Group	RG0
Total power consumption (W)	17
Electrical protection	Class I
Dimmable	No
Average life (Nominal) (h)	30000
Housing colour	White
IP rating	IP44
IK rating	IK03
Product EAN number	5410288432823
Lamps	No


PHOTOMETRY

SylCircle SYLCIRCLE 17W 3000K 0043282


0.5	2.38 2.13	E:0° E:C90° E:C0°	109 41 34
1.0	4.76 4.25	E:0° E:C90° E:C0°	382 10 14
1.5	7.14 6.38	E:0° E:C90° E:C0°	187 7 9
2.0	9.52 8.50	E:0° E:C90° E:C0°	88 3 3
2.5	11.89 10.63	E:0° E:C90° E:C0°	66 2 2
3.0	14.27 12.75	E:0° E:C90° E:C0°	39 1 1

Distance [m] Core diameter [m] Illuminance [lx]

— C0 - C180 (Half beam angle: 135.4°)
— C90 - C270 (Half beam angle: 134.4°)

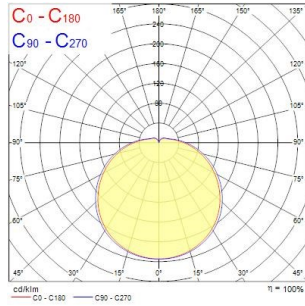

TECHNICAL DRAWINGS

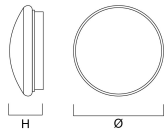

Version	Ø	H
6W	180	75
12W	250	80
17/18W	330	96
24W	360	100