


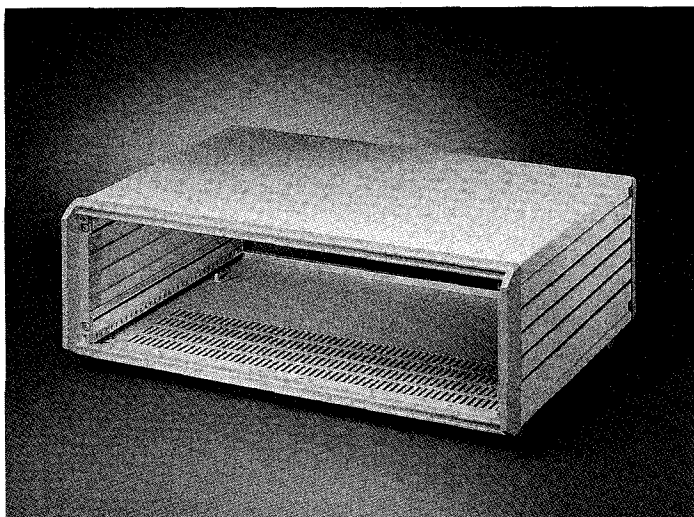
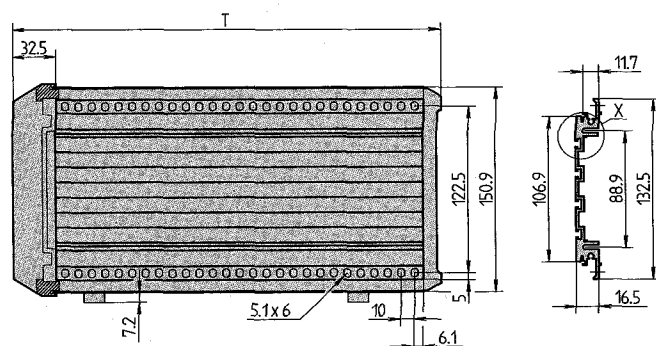


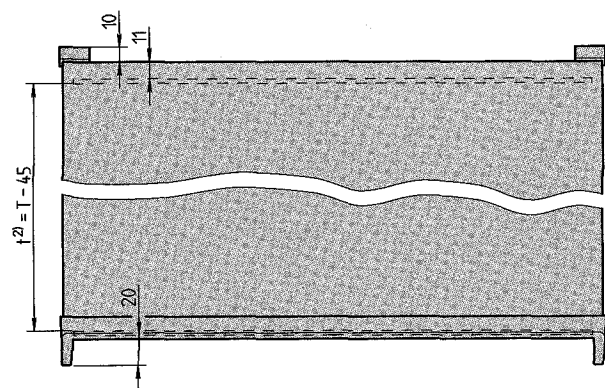

Dimensions

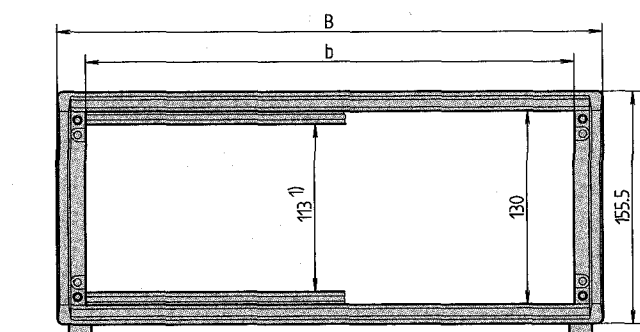


Detail "X"

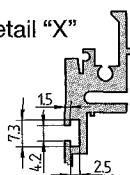

- 1) Clear width between the horizontal rails
- 2) Max. mounting depth

PPA43731 PPA43728
PPA43795 PPA43827

Basic case 3 U

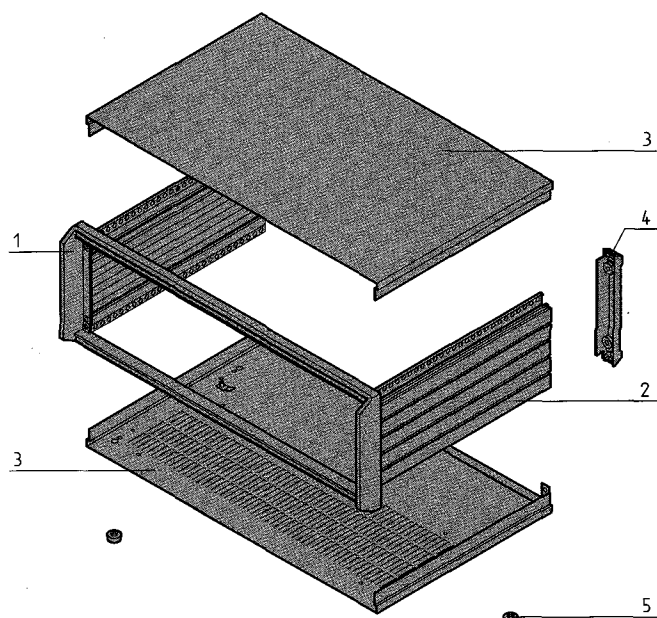

PPA43734

Delivery comprises

Item	Qty	Description	Material	Finish	Notes
1	1	Frame	Al die-cast	painted RAL 7030	
2	2	Side plate	Al extrusion	painted RAL 7035	
3	2	Top/bottom cover	Al 1 mm	Visible surface painted RAL 7035	with GND/earthing connection, base cover with 4 rows of vent slots
4	2	Rear foot	ABS	RAL 7030	UL 94 V-0
5	4	Anti-skid foot	PC	black	UL 94 V-0

Delivery: items 1-4 assembled

Ordering basic case 3 U

Usable width w HP	mm	Dimensions mm Width W	Depth D	Order No. for 1 basic case
28	147.3	185.9	256	10850-013
			316	10850-014
42	218.4	257.0	256	10850-015
			316	10850-016
			376	10850-017
63	325.1	363.7	256	10850-019
			316	10850-020
84	431.8	470.3	376	10850-021
			256	10850-023
			316	10850-024
			376	10850-025
			436	10850-026
			496	10850-027

Drawing reference:

$b = w$
 $B = W$
 $t = d$
 $T = D$