


Product data sheet

Characteristics

AZ5CE005

single conductor insulated cable end - medium
- 0.5 mm² - white

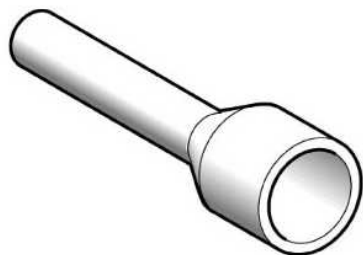

Main

Commercial Status	End of commercialisation
Range of product	Cable ends
Product or component type	Cable end
Cable end size	Medium
Standards	NF C 63-023
Type of packing	Dispenser pack
Quantity per set	5 sets of 200
Cable cross section	0 in ² (0.5 mm ²)

Complementary

Cable end type	Single conductor
Additional information	Without marker tag holder
Colour	White
Bezel material	Halogen-free plastic
Tube material	Copper conforming to ISO 1337
Number of cables	1
AWG gauge	22
Bezel size	Ø 3 mm
Tube diameter	0.06 in (1.4 mm)
Length	0.51 in (13 mm)
Tube length	0.32 in (8.2 mm)
CAD overall width	0.12 in (3 mm)
CAD overall height	0.12 in (3 mm)
CAD overall depth	0.51 in (13 mm)
Product weight	0.31 lb(US) (0.14 kg)

Environment

Product certifications	UL
Ambient air temperature for operation	-4...221 °F (-20...105 °C)

Ordering and shipping details

Category	22621 - IEC PANEL ACCESSORIES
Discount Schedule	I
Nbr. of units in pkg.	1000
Package weight(Lbs)	0.01
Returnability	N

Contractual warranty

Period	18 months
--------	-----------