


KEMET Part Number: SSHB10H-10064
(UALSB110064000)

KEMET, SSHB10H, AC Line Filters, Dual Mode, 6400 uH

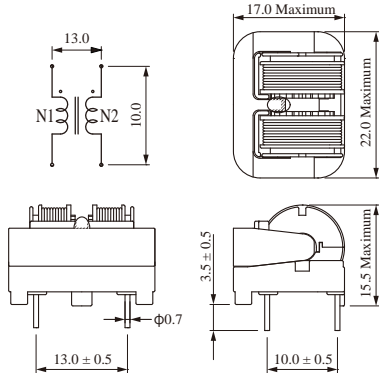

Dimensions

L	22mm MAX
T	17mm MAX
H	15.5mm MAX
LL	3.5mm +/-0.5mm
S	13mm +/-0.5mm

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	300
Weight:	10 g

General Information

Series:	SSHB10H
Style:	Through-Hole
RoHS:	Yes
Notes:	Marking: 10 Lot No.
Miscellaneous:	Temperature Rise Maximum: 65 K

Specifications

Voltage AC:	250 VAC
Inductance:	6.4 mH (10 kHz)
Current:	1 A
Temperature Range:	-25/+130°C
DC Resistance:	480 mOhms