

PRODUCT DETAILS

ARTICLE: [32509BFD](#)



WHEEL LB 125X40/40 PB BOLT HOLE FORK M22 /50 HOLE 14

Wheel series LB

Wheels with black polyamide 6 centre, blue elastic non-marking rubber mould-on solid tyre available with ball bearings, standard or stainless steel roller bearings of plain bore.
Plain bore wheel.




Castor series M22

M22 series, Medium-light pressed steel fork assemblies; swivel version has double ball raceways. Zincplated.

Single bolt hole fixing for bolt diam. 12-14 mm.

Technical data

| | | |
|----------------------|---|----------|
| Wheel diameter | D | 125 mm |
| Tyre width | E | 40,0 mm |
| Bore diameter | d | 15 mm |
| Weight article | | 1,160 kg |
| Hub width | L | 40 mm |
| Overall height | H | 159 mm |
| Fixing bolt diameter | g | M12-14 |
| Offset | F | 49 mm |
| Fork width | U | 50 mm |
| Load Capacity | | 200 kg |

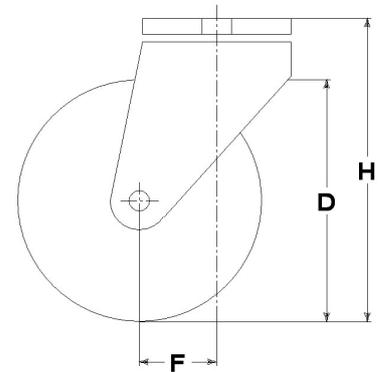

Related Articles

- Spare part wheel: [30114B](#)
- Version with thread-guards: [32509BPFFD](#)
- Version with footguard: [32509BPPFD](#)
- Version with trailing brake: [32509BFRFD](#)
- Version with trailing brake and footguard: [32509BFRPPFD](#)

GENERAL INFORMATION / RECOMMENDATIONS AND WARNINGS

The cited text and the complete catalogue in their most up-dated versions are available in the OEM's website page www.lagspa.it/downloads. The dimensions, descriptions, specifications and illustrations herein are indicative and subject to variations without notice. The fact that products are illustrated herein does not necessarily imply they are available from stock nor does it place us under any obligation to supply them. Tests carried out refer to the original products with original accessories: the replacement of one of the components with others of different manufacture might prevent the same results from being achieved and will automatically invalidate any guarantee. Please contact our technical service concerning any special application.