


TLS 2200®/TLS PC Link™ Labels

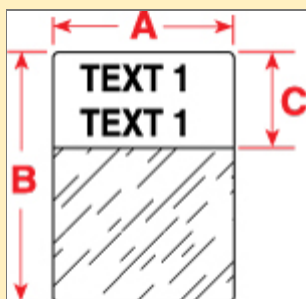

Labels for the TLS 2200® & TLS PC Link™ Thermal Transfer Portable Printers. Please Note: This material is UL recognised with its respective ribbon. See the "Recommended Ribbon Series" for the appropriate ribbon to use.

Overview

Specifications

Article Number: 018432

Order Reference: PTL-32-427

Size - Width (mm): 38.1

Size - Height (mm): 38.1

Finish: Matt

Colour: White/Transparent

Printable Area - Width (mm): 38.1

Printable Area - Height (mm): 12.7

Material Type: Self-Laminating Vinyl

Brady Material Number: [B-427](#)

Adhesive: [Acrylic](#)

Approval/Compliance: UL Recognised

Max. Service Temp. °C: 70

Special Properties: Excellent abrasion and smudge resistance, Excellent water & oil resistance, Self-Extinguishing, Self-Laminating

QTY. per Row: 1

Max. Lines of Text: 5

Max. Characters per Line: 37

Printer Compatibility: TLS2200, TLSPCLink

Voice/Data Application: Communications Cables

Wire Gauge: 10 to 4

Industry: Data Communications, Electrical

Application(s): Communications Cables, Panel Identification, Voice/Data Identification, Wire & Cable Marking

For further information on this product or for details of a local Brady Authorised Distributor, please use the "Contact Us" button