


Surveillance two wire earpiece with acoustic tube

RS Stock number 781-1709

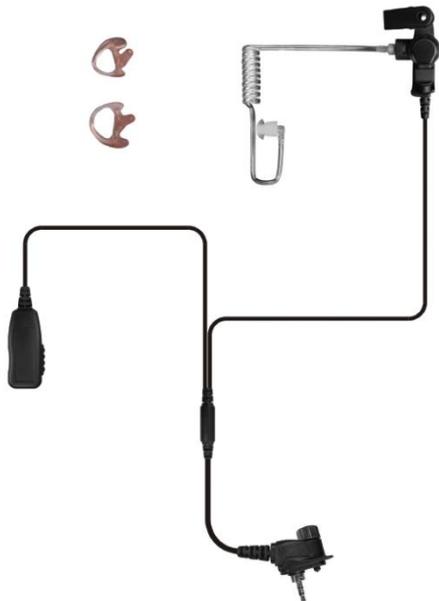

Features:

- Surgical grade acoustic tube; discreet and comfortable
- Quick-fasten secure structure
- Environmental PU cable reinforced with Kevlar
- Optional ear mold allows ambient sounds
- Discreet communication in sensitive environments
- Suitable for many applications including; security personnel, hotel and catering staff, etc.



Technical Specification

Speaker:

Dimensions: Dia 16.2mm x 10.6mm

Impedance: $250 \pm 50\Omega$

Sound Pressure Level: $104 \pm 3\text{db}$ @1000Hz

Microphone:

- Type: Electric Condenser Microphone
- Impedance: 2.2 k Ω
- Sensitivity: $-40 \pm 3\text{db}$ @1000Hz
(0db = 1V/PA)
- Operating Voltage: 11.1-10VDC

PTT:

Dimensions: 34.9 x 14.2 x 11.8mm