


1748-S

Self-locking stainless steel cable ties

CE

Material: stainless steel AISI 304
 Locking device: roller ball type
 Self-extinguishing class: non-flammable
 Plenum rating: AH-1
 UV resistance: excellent
 Working temperature: -60 °C ÷ +300 °C
 Minimum installation temperature: -60 °C
 Resistance to chemicals: excellent
 Reference standards: EN 62275:2015-02
 Classification: type 2 (EN); type 2 (UL)

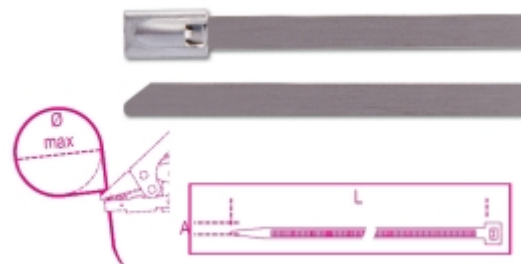

	art.	A mm	L mm	ØMAX mm	Trazione N
BMS1345	BMS1345	4.6	125	38	890
BMS2045	BMS2045	4.6	200	61.9	890
BMS2079	BMS2079	7.9	200	61.9	1500
BMS3045	BMS3045	4.6	290	90.6	890
BMS3079	BMS3079	7.9	300	90.6	1500
BMS3745	BMS3745	4.6	360	112.8	890
BMS3779	BMS3779	7.9	360	112.8	1500
BMS5079	BMS5079	7.9	500	163.8	1500
BMS5245	BMS5245	4.6	520	163.8	890
BMS6845	BMS6845	4.6	680	214.8	890
BMS6879	BMS6879	7.9	680	214.8	1500
BMS8445	BMS8445	4.6	840	265.7	890
BMS8479	BMS8479	7.9	840	265.7	1500