

# Personal Shredders

## Powershred® 6M Mini-Cut (P-4) Shredder – SafetyLock

Home Office & Deskside (1 User)


### Features:

- Shreds 10 sheets of paper at a time into 4x12mm mini-cut particles (Security Level P-4) – approximately 1299 particles per A4 sheet
- Safety Lock manually disables the shredder to prevent accidental activation
- Shreds non-stop for up to 5 minutes
- 13L lift-off head bin for easy disposal of paper waste
- Also shreds staples, paper clips and credit cards
- 2-year machine / 3-year cutter warranty



### Specifications

|                                              |                                   |
|----------------------------------------------|-----------------------------------|
| Sheet capacity                               | 6                                 |
| Bin Capacity                                 | 13L (Lift-off Head) (150 sheets)  |
| Cut-type                                     | Mini-cut (4x12mm)                 |
| Security Level                               | P-4 (1299 particles per A4 sheet) |
| Feed Type                                    | Manual                            |
| Runtime (minutes)                            | 5 on / 30 off                     |
| Throat width (mm)                            | 220mm                             |
| Also shreds                                  |                                   |
| Colour                                       | Black                             |
| Product Dimensions (H x W x D) / mm          | 373 x 313 x 175                   |
| Product Weight                               | 3.2 kg                            |
| Retail Packaging Dimensions (H x W x D) / mm | 333 x 300 x 171                   |
| Retail Packaging Weight                      | 3.7 kg                            |
| Outer Carton Dimensions (H x W x D) / mm     | 380 x 316 x 361                   |
| Outer Carton Weight                          | 9.4 kg                            |
| Quantity per Outer Carton                    | 2                                 |
| Country of Origin                            | China                             |
| Warranty                                     | 2-year machine / 3-year cutters   |

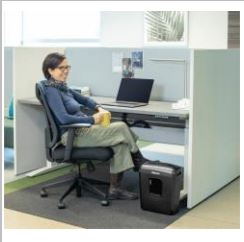

### Recommended

|            |         |
|------------|---------|
| Oil 355ml  | 3608601 |
| Oil 120ml  | 3608501 |
| Oil Sheets | 4025601 |


|           |         |                   |                     |
|-----------|---------|-------------------|---------------------|
| Code (EU) | 4631101 | UPC: 043859743568 | SCS: 50043859743563 |
| Code (UK) | 4631201 | UPC: 043859743575 | SCS: 50043859743570 |

# Personal Shredders


## Powershred® 6M Mini-Cut (P-4) Shredder – SafetyLock

Home Office & Deskside (1 User)

### Recyclability:

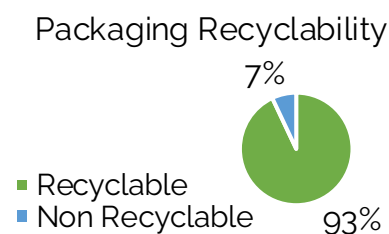

**Packaging Recyclability**  
Percentage of the packaging by weight that can be sent for recycling

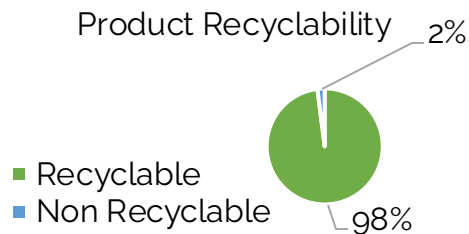

**Product Recyclability**  
Percentage of the product by weight that can easily be separated and sent for recycling

### Certifications:



### Other information:

**Servicing:** Relevant info about servicing the shredder (for example oiling the machine) can be found in the Product Manual.

#### After Sales Support:

- Repairable: YES
- Availability of Spare Parts: YES
- Returnable: Yes, as per Fellowes Trading Conditions

**Declaration of Conformity:** The declaration of conformity can be found on the back of the Product Manual that comes with the shredder.

Digital versions of the manual can be found on your local Fellowes.com website in the 'downloads tab' of this product

**Support:** This unit comes with a 2-year machine. For product related questions, or further information, our dedicated Customer Service team can be reached at our freephone number 00800 1810 1810