


Coupling hub EAMC-H-25-10-GB8-9

Part number: 8228651

FESTO

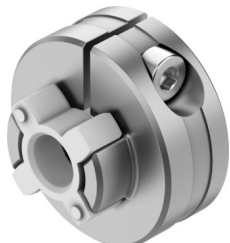

 [General operating condition](#)

Data sheet

Feature	Value
Mounting diameter 1	9 mm
Size	15/25
Nominal length	15.4 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Ambient temperature	-25 °C ... 60 °C
Mass moment of inertia	1.04 kgmm ²
Transmittable torque	2 Nm
Product weight	13 g
Note on materials	RoHS compliant