



- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18
- 19

MATERIAL

AISI 316L stainless steel.

PACKING RING


- H: H-NBR synthetic rubber, hardness 85 +/-5 Shore A, in blue, FDA compliant, resistant from -25°C to +150°C.
- E: EPDM synthetic rubber, hardness 85 +/-5 Shore A, in blue, FDA compliant, resistant from -40°C to +120°C.
- F: FKM synthetic rubber, hardness 85 +/-5 Shore A, in blue, FDA compliant, resistant from -5 °C to +200 °C.


STANDARD EXECUTIONS

- **NT-HD-SST-MT-H**: threaded blind hole, sandblasted matte finish, (RA < 0.8µ), H-NBR packing ring.
- **NT-HD-SST-MT-E**: threaded blind hole, sandblasted matte finish, (RA < 0.8µ), EPDM packing ring.
- **NT-HD-SST-MT-F**: threaded blind hole, sandblasted matte finish, (RA < 0.8µ), FKM packing ring.
- **NT-HD-SST-PL-H**: threaded blind hole, mirror polished finish (RA < 0.8µ), H-NBR packing ring.
- **NT-HD-SST-PL-E**: threaded blind hole, mirror polished finish (RA < 0.8µ), EPDM packing ring.
- **NT-HD-SST-PL-F**: threaded blind hole, mirror polished finish (RA < 0.8µ), FKM packing ring.
- **NT-HD-SST-p-MT-H**: threaded screw, sandblasted matte finish (RA < 0.8µ), H-NBR packing ring.
- **NT-HD-SST-p-MT-E**: threaded screw, sandblasted matte finish (RA < 0.8µ), EPDM packing ring.
- **NT-HD-SST-p-MT-F**: Threaded screw, sandblasted matte finish (RA < 0.8µ), FKM packing ring.
- **NT-HD-SST-p-PL-H**: threaded screw, mirror polished finish (RA < 0.8µ), H-NBR packing ring.
- **NT-HD-SST-p-PL-E**: threaded screw, mirror polished finish (RA < 0.8µ), EPDM packing ring.
- **NT-HD-SST-p-PL-F**: threaded screw, mirror polished finish (RA < 0.8µ), FKM packing ring.

FEATURES AND APPLICATIONS

The NT-HD-SST screws and nuts are accessories for securing the leveling feet, certified according to EHEDG guidelines, that are designed for use in environments where a high level of hygiene is required. The presence of the special packing ring seals the thread from the external environment, preventing the access of impurities. The finish quality, angular seal and absence of recesses, prevents dirt adherence and facilitates cleaning. See technical data Hygienic Design (see page -).

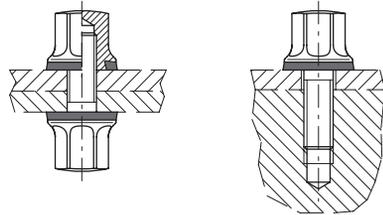

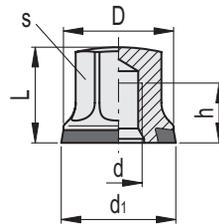

NT-HD-SST-MT-H



| Code | Description | D | d | L | d1 | h | s | ⚖️ |
|--------|--------------------|----|-----|------|------|------|----|-----|
| 321061 | NT-HD-SST-M4-MT-H | 11 | M4 | 9.5 | 11.8 | 6 | 7 | 3 |
| 321101 | NT-HD-SST-M5-MT-H | 12 | M5 | 10 | 12.8 | 6 | 8 | 4 |
| 321111 | NT-HD-SST-M6-MT-H | 14 | M6 | 12 | 14.8 | 7.5 | 10 | 10 |
| 321121 | NT-HD-SST-M8-MT-H | 18 | M8 | 14.5 | 18.8 | 9.5 | 13 | 15 |
| 321131 | NT-HD-SST-M10-MT-H | 21 | M10 | 18 | 21.8 | 12 | 16 | 23 |
| 320902 | NT-HD-SST-M12-MT-H | 25 | M12 | 21 | 25.8 | 14.5 | 18 | 44 |
| 320912 | NT-HD-SST-M16-MT-H | 32 | M16 | 26 | 32.8 | 17 | 24 | 83 |
| 320922 | NT-HD-SST-M20-MT-H | 40 | M20 | 32 | 40.8 | 22 | 30 | 150 |

NT-HD-SST-MT-E

| Code | Description | D | d | L | d1 | h | s | ⚖️ |
|--------|--------------------|----|-----|------|------|------|----|-----|
| 321062 | NT-HD-SST-M4-MT-E | 11 | M4 | 9.5 | 11.8 | 6 | 7 | 3 |
| 321102 | NT-HD-SST-M5-MT-E | 12 | M5 | 10 | 12.8 | 6 | 8 | 8 |
| 321112 | NT-HD-SST-M6-MT-E | 14 | M6 | 12 | 14.8 | 7.5 | 10 | 10 |
| 321122 | NT-HD-SST-M8-MT-E | 18 | M8 | 14.5 | 18.8 | 9.5 | 13 | 17 |
| 321132 | NT-HD-SST-M10-MT-E | 21 | M10 | 18 | 21.8 | 12 | 16 | 19 |
| 320901 | NT-HD-SST-M12-MT-E | 25 | M12 | 21 | 25.8 | 14.5 | 18 | 44 |
| 320911 | NT-HD-SST-M16-MT-E | 32 | M16 | 26 | 32.8 | 17 | 24 | 83 |
| 320921 | NT-HD-SST-M20-MT-E | 40 | M20 | 32 | 40.8 | 22 | 30 | 150 |

NT-HD-SST-MT-F

| Code | Description | D | d | L | d1 | h | s | ⚖️ |
|--------|--------------------|----|-----|------|------|------|----|-----|
| 321063 | NT-HD-SST-M4-MT-F | 11 | M4 | 9.5 | 11.8 | 6 | 7 | 3 |
| 321103 | NT-HD-SST-M5-MT-F | 12 | M5 | 10 | 12.8 | 6 | 8 | 8 |
| 321113 | NT-HD-SST-M6-MT-F | 14 | M6 | 12 | 14.8 | 7.5 | 10 | 10 |
| 321123 | NT-HD-SST-M8-MT-F | 18 | M8 | 14.5 | 18.8 | 9.5 | 13 | 17 |
| 321128 | NT-HD-SST-M10-MT-F | 21 | M10 | 18 | 21.8 | 12 | 16 | 25 |
| 321133 | NT-HD-SST-M12-MT-F | 25 | M12 | 21 | 25.8 | 14.5 | 18 | 45 |
| 321135 | NT-HD-SST-M16-MT-F | 32 | M16 | 26 | 32.8 | 17 | 24 | 84 |
| 321139 | NT-HD-SST-M20-MT-F | 40 | M20 | 32 | 40.8 | 22 | 30 | 150 |

NT-HD-SST-PL-H




| Code | Description | D | d | L | d1 | h | s | ⚖️ |
|--------|--------------------|----|-----|------|------|------|----|-----|
| 321066 | NT-HD-SST-M4-PL-H | 11 | M4 | 9.5 | 11.8 | 6 | 7 | 3 |
| 321106 | NT-HD-SST-M5-PL-H | 12 | M5 | 10 | 12.8 | 6 | 8 | 8 |
| 321116 | NT-HD-SST-M6-PL-H | 14 | M6 | 12 | 14.8 | 7.5 | 10 | 12 |
| 321126 | NT-HD-SST-M8-PL-H | 18 | M8 | 14.5 | 18.8 | 9.5 | 13 | 14 |
| 321136 | NT-HD-SST-M10-PL-H | 21 | M10 | 18 | 21.8 | 12 | 16 | 23 |
| 320904 | NT-HD-SST-M12-PL-H | 25 | M12 | 21 | 25.8 | 14.5 | 18 | 44 |
| 320914 | NT-HD-SST-M16-PL-H | 32 | M16 | 26 | 32.8 | 17 | 24 | 83 |
| 320924 | NT-HD-SST-M20-PL-H | 40 | M20 | 32 | 40.8 | 22 | 30 | 150 |

NT-HD-SST-PL-E

| Code | Description | D | d | L | d1 | h | s | ⚖️ |
|--------|--------------------|----|-----|------|------|------|----|-----|
| 321067 | NT-HD-SST-M4-PL-E | 11 | M4 | 9.5 | 11.8 | 6 | 7 | 3 |
| 321107 | NT-HD-SST-M5-PL-E | 12 | M5 | 10 | 12.8 | 6 | 8 | 8 |
| 321117 | NT-HD-SST-M6-PL-E | 14 | M6 | 12 | 14.8 | 7.5 | 10 | 10 |
| 321127 | NT-HD-SST-M8-PL-E | 18 | M8 | 14.5 | 18.8 | 9.5 | 13 | 17 |
| 321137 | NT-HD-SST-M10-PL-E | 21 | M10 | 18 | 21.8 | 12 | 16 | 19 |
| 320903 | NT-HD-SST-M12-PL-E | 25 | M12 | 21 | 25.8 | 14.5 | 18 | 44 |
| 320913 | NT-HD-SST-M16-PL-E | 32 | M16 | 26 | 32.8 | 17 | 24 | 83 |
| 320923 | NT-HD-SST-M20-PL-E | 40 | M20 | 32 | 40.8 | 22 | 30 | 150 |


NT-HD-SST-PL-F

| Code | Description | D | d | L | d1 | h | s | ⚖️ |
|--------|--------------------|----|-----|------|------|------|----|-----|
| 321068 | NT-HD-SST-M4-PL-F | 11 | M4 | 9.5 | 11.8 | 6 | 7 | 3 |
| 321108 | NT-HD-SST-M5-PL-F | 12 | M5 | 10 | 12.8 | 6 | 8 | 8 |
| 321118 | NT-HD-SST-M6-PL-F | 14 | M6 | 12 | 14.8 | 7.5 | 10 | 10 |
| 321124 | NT-HD-SST-M8-PL-F | 18 | M8 | 14.5 | 18.8 | 9.5 | 13 | 17 |
| 321129 | NT-HD-SST-M10-PL-F | 21 | M10 | 18 | 21.8 | 12 | 16 | 25 |
| 321134 | NT-HD-SST-M12-PL-F | 25 | M12 | 21 | 25.8 | 14.5 | 18 | 45 |
| 321138 | NT-HD-SST-M16-PL-F | 32 | M16 | 26 | 32.8 | 17 | 24 | 84 |
| 321140 | NT-HD-SST-M20-PL-F | 40 | M20 | 32 | 40.8 | 22 | 30 | 150 |

 

Leveling feet and supports

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18
- 19

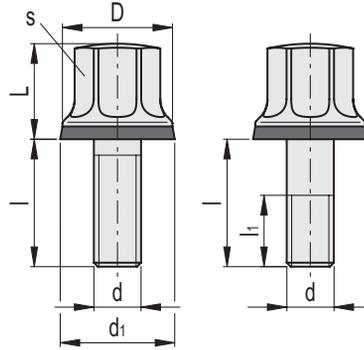


NT-HD-SST-p-MT-H

| Code | Description | D | d | L | l | l1 | d1 | s | ⚖️ |
|--------|-------------------------|----|-----|------|----|----|------|----|-----|
| 321071 | NT-HD-SST-p-M4x8-MT-H | 11 | M4 | 9.5 | 8 | - | 11.8 | 7 | 4 |
| 321079 | NT-HD-SST-p-M4x10-MT-H | 11 | M4 | 9.5 | 10 | - | 11.8 | 7 | 5 |
| 321081 | NT-HD-SST-p-M4x12-MT-H | 11 | M4 | 9.5 | 12 | - | 11.8 | 7 | 5 |
| 321091 | NT-HD-SST-p-M4x16-MT-H | 11 | M4 | 9.5 | 16 | 14 | 11.8 | 7 | 5 |
| 321141 | NT-HD-SST-p-M5x10-MT-H | 12 | M5 | 10 | 10 | - | 12.8 | 8 | 7 |
| 321151 | NT-HD-SST-p-M5x16-MT-H | 12 | M5 | 10 | 16 | - | 12.8 | 8 | 9 |
| 321161 | NT-HD-SST-p-M5x20-MT-H | 12 | M5 | 10 | 20 | 16 | 12.8 | 8 | 11 |
| 321171 | NT-HD-SST-p-M6x12-MT-H | 14 | M6 | 12 | 12 | - | 14.8 | 10 | 11 |
| 321181 | NT-HD-SST-p-M6x16-MT-H | 14 | M6 | 12 | 16 | - | 14.8 | 10 | 12 |
| 321191 | NT-HD-SST-p-M6x20-MT-H | 14 | M6 | 12 | 20 | - | 14.8 | 10 | 17 |
| 321201 | NT-HD-SST-p-M6x25-MT-H | 14 | M6 | 12 | 25 | - | 14.8 | 10 | 13 |
| 321211 | NT-HD-SST-p-M6x30-MT-H | 14 | M6 | 12 | 30 | 18 | 14.8 | 10 | 14 |
| 321221 | NT-HD-SST-p-M8x16-MT-H | 18 | M8 | 14.5 | 16 | - | 18.8 | 13 | 23 |
| 321231 | NT-HD-SST-p-M8x20-MT-H | 18 | M8 | 14.5 | 20 | - | 18.8 | 13 | 1 |
| 321241 | NT-HD-SST-p-M8x25-MT-H | 18 | M8 | 14.5 | 25 | - | 18.8 | 13 | 1 |
| 321251 | NT-HD-SST-p-M8x30-MT-H | 18 | M8 | 14.5 | 30 | - | 18.8 | 13 | 1 |
| 321261 | NT-HD-SST-p-M8x40-MT-H | 18 | M8 | 14.5 | 40 | 22 | 18.8 | 13 | 1 |
| 321271 | NT-HD-SST-p-M10x20-MT-H | 21 | M10 | 18 | 20 | - | 21.8 | 16 | 1 |
| 321281 | NT-HD-SST-p-M10x25-MT-H | 21 | M10 | 18 | 25 | - | 21.8 | 16 | 43 |
| 321291 | NT-HD-SST-p-M10x30-MT-H | 21 | M10 | 18 | 30 | - | 21.8 | 16 | 41 |
| 321301 | NT-HD-SST-p-M10x40-MT-H | 21 | M10 | 18 | 40 | 26 | 21.8 | 16 | 6 |
| 321311 | NT-HD-SST-p-M10x50-MT-H | 21 | M10 | 18 | 50 | 26 | 21.8 | 16 | 1 |
| 321321 | NT-HD-SST-p-M12x25-MT-H | 25 | M12 | 21 | 25 | - | 25.8 | 18 | 79 |
| 321331 | NT-HD-SST-p-M12x30-MT-H | 25 | M12 | 21 | 30 | - | 25.8 | 18 | 70 |
| 321341 | NT-HD-SST-p-M12x40-MT-H | 25 | M12 | 21 | 40 | 30 | 25.8 | 18 | 78 |
| 321351 | NT-HD-SST-p-M12x50-MT-H | 25 | M12 | 21 | 50 | 30 | 25.8 | 18 | 102 |
| 321361 | NT-HD-SST-p-M12x60-MT-H | 25 | M12 | 21 | 60 | 30 | 25.8 | 18 | 111 |
| 321371 | NT-HD-SST-p-M16x30-MT-H | 32 | M16 | 26 | 30 | - | 32.8 | 24 | 157 |
| 321381 | NT-HD-SST-p-M16x40-MT-H | 32 | M16 | 26 | 40 | - | 32.8 | 24 | 173 |
| 321391 | NT-HD-SST-p-M16x50-MT-H | 32 | M16 | 26 | 50 | 38 | 32.8 | 24 | 189 |
| 321401 | NT-HD-SST-p-M16x60-MT-H | 32 | M16 | 26 | 60 | 38 | 32.8 | 24 | 187 |
| 321411 | NT-HD-SST-p-M16x70-MT-H | 32 | M16 | 26 | 70 | 38 | 32.8 | 24 | 204 |
| 320932 | NT-HD-SST-p-M20x40-MT-H | 40 | M20 | 32 | 40 | 46 | 40.8 | 30 | 296 |
| 320942 | NT-HD-SST-p-M20x60-MT-H | 40 | M20 | 32 | 60 | 46 | 40.8 | 30 | 346 |

NT-HD-SST-p-MT-E

| Code | Description | D | d | L | l | l1 | d1 | s | ⚖️ |
|--------|-------------------------|----|-----|------|----|----|------|----|-----|
| 321072 | NT-HD-SST-p-M4x8-MT-E | 11 | M4 | 9.5 | 8 | - | 11.8 | 7 | 4 |
| 321078 | NT-HD-SST-p-M4x10-MT-E | 11 | M4 | 9.5 | 10 | - | 11.8 | 7 | 5 |
| 321082 | NT-HD-SST-p-M4x12-MT-E | 11 | M4 | 9.5 | 12 | - | 11.8 | 7 | 5 |
| 321092 | NT-HD-SST-p-M4x16-MT-E | 11 | M4 | 9.5 | 16 | 14 | 11.8 | 7 | 13 |
| 321142 | NT-HD-SST-p-M5x10-MT-E | 12 | M5 | 10 | 10 | - | 12.8 | 8 | 13 |
| 321152 | NT-HD-SST-p-M5x16-MT-E | 12 | M5 | 10 | 16 | - | 12.8 | 8 | 11 |
| 321162 | NT-HD-SST-p-M5x20-MT-E | 12 | M5 | 10 | 20 | 16 | 12.8 | 8 | 11 |
| 321172 | NT-HD-SST-p-M6x12-MT-E | 14 | M6 | 12 | 12 | - | 14.8 | 10 | 14 |
| 321182 | NT-HD-SST-p-M6x16-MT-E | 14 | M6 | 12 | 16 | - | 14.8 | 10 | 15 |
| 321192 | NT-HD-SST-p-M6x20-MT-E | 14 | M6 | 12 | 20 | - | 14.8 | 10 | 13 |
| 321202 | NT-HD-SST-p-M6x25-MT-E | 14 | M6 | 12 | 25 | - | 14.8 | 10 | 13 |
| 321212 | NT-HD-SST-p-M6x30-MT-E | 14 | M6 | 12 | 30 | 18 | 14.8 | 10 | 18 |
| 321222 | NT-HD-SST-p-M8x16-MT-E | 18 | M8 | 14.5 | 16 | - | 18.8 | 13 | 24 |
| 321232 | NT-HD-SST-p-M8x20-MT-E | 18 | M8 | 14.5 | 20 | - | 18.8 | 13 | 28 |
| 321242 | NT-HD-SST-p-M8x25-MT-E | 18 | M8 | 14.5 | 25 | - | 18.8 | 13 | 28 |
| 321252 | NT-HD-SST-p-M8x30-MT-E | 18 | M8 | 14.5 | 30 | - | 18.8 | 13 | 30 |
| 321262 | NT-HD-SST-p-M8x40-MT-E | 18 | M8 | 14.5 | 40 | 22 | 18.8 | 13 | 33 |
| 321272 | NT-HD-SST-p-M10x20-MT-E | 21 | M10 | 18 | 20 | - | 21.8 | 16 | 49 |
| 321282 | NT-HD-SST-p-M10x25-MT-E | 21 | M10 | 18 | 25 | - | 21.8 | 16 | 52 |
| 321292 | NT-HD-SST-p-M10x30-MT-E | 21 | M10 | 18 | 30 | - | 21.8 | 16 | 54 |
| 321302 | NT-HD-SST-p-M10x40-MT-E | 21 | M10 | 18 | 40 | 26 | 21.8 | 16 | 59 |
| 321312 | NT-HD-SST-p-M10x50-MT-E | 21 | M10 | 18 | 50 | 26 | 21.8 | 16 | 64 |
| 321322 | NT-HD-SST-p-M12x25-MT-E | 25 | M12 | 21 | 25 | - | 25.8 | 18 | 79 |
| 321332 | NT-HD-SST-p-M12x30-MT-E | 25 | M12 | 21 | 30 | - | 25.8 | 18 | 70 |
| 321342 | NT-HD-SST-p-M12x40-MT-E | 25 | M12 | 21 | 40 | 30 | 25.8 | 18 | 77 |
| 321352 | NT-HD-SST-p-M12x50-MT-E | 25 | M12 | 21 | 50 | 30 | 25.8 | 18 | 102 |
| 321362 | NT-HD-SST-p-M12x60-MT-E | 25 | M12 | 21 | 60 | 30 | 25.8 | 18 | 111 |
| 321372 | NT-HD-SST-p-M16x30-MT-E | 32 | M16 | 26 | 30 | - | 32.8 | 24 | 157 |
| 321382 | NT-HD-SST-p-M16x40-MT-E | 32 | M16 | 26 | 40 | - | 32.8 | 24 | 173 |
| 321392 | NT-HD-SST-p-M16x50-MT-E | 32 | M16 | 26 | 50 | 38 | 32.8 | 24 | 189 |
| 321402 | NT-HD-SST-p-M16x60-MT-E | 32 | M16 | 26 | 60 | 38 | 32.8 | 24 | 187 |
| 321412 | NT-HD-SST-p-M16x70-MT-E | 32 | M16 | 26 | 70 | 38 | 32.8 | 24 | 221 |
| 320931 | NT-HD-SST-p-M20x40-MT-E | 40 | M20 | 32 | 40 | 46 | 40.8 | 30 | 296 |
| 320941 | NT-HD-SST-p-M20x60-MT-E | 40 | M20 | 32 | 60 | 46 | 40.8 | 30 | 346 |

Levelling feet and supports

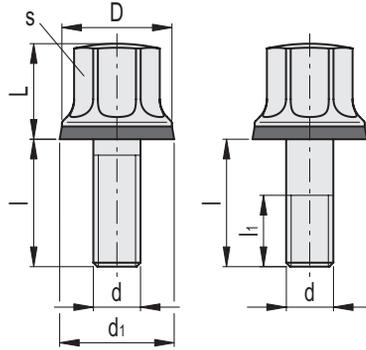

NT-HD-SST-MT-F



| Code | Description | D | d | L | l | l1 | d1 | s | ⚖ |
|--------|-------------------------|----|-----|------|----|----|------|----|-----|
| 321073 | NT-HD-SST-p-M4x8-MT-F | 11 | M4 | 9.5 | 8 | - | 11.8 | 7 | 5 |
| 321084 | NT-HD-SST-p-M4x10-MT-F | 11 | M4 | 9.5 | 10 | - | 11.8 | 7 | 6 |
| 321088 | NT-HD-SST-p-M4x12-MT-F | 11 | M4 | 9.5 | 12 | - | 11.8 | 7 | 7 |
| 321093 | NT-HD-SST-p-M4x16-MT-F | 11 | M4 | 9.5 | 16 | 14 | 11.8 | 7 | 8 |
| 321143 | NT-HD-SST-p-M5x10-MT-F | 12 | M5 | 10 | 10 | - | 12.8 | 8 | 10 |
| 321153 | NT-HD-SST-p-M5x16-MT-F | 12 | M5 | 10 | 16 | - | 12.8 | 8 | 11 |
| 321163 | NT-HD-SST-p-M5x20-MT-F | 12 | M5 | 10 | 20 | 16 | 12.8 | 8 | 12 |
| 321173 | NT-HD-SST-p-M6x12-MT-F | 14 | M6 | 12 | 12 | - | 14.8 | 10 | 14 |
| 321183 | NT-HD-SST-p-M6x16-MT-F | 14 | M6 | 12 | 16 | - | 14.8 | 10 | 15 |
| 321193 | NT-HD-SST-p-M6x20-MT-F | 14 | M6 | 12 | 20 | - | 14.8 | 10 | 16 |
| 321203 | NT-HD-SST-p-M6x25-MT-F | 14 | M6 | 12 | 25 | - | 14.8 | 10 | 17 |
| 321213 | NT-HD-SST-p-M6x30-MT-F | 14 | M6 | 12 | 30 | 18 | 14.8 | 10 | 18 |
| 321223 | NT-HD-SST-p-M8x16-MT-F | 18 | M8 | 14.5 | 16 | - | 18.8 | 13 | 33 |
| 321233 | NT-HD-SST-p-M8x20-MT-F | 18 | M8 | 14.5 | 20 | - | 18.8 | 13 | 24 |
| 321243 | NT-HD-SST-p-M8x25-MT-F | 18 | M8 | 14.5 | 25 | - | 18.8 | 13 | 26 |
| 321253 | NT-HD-SST-p-M8x30-MT-F | 18 | M8 | 14.5 | 30 | - | 18.8 | 13 | 27 |
| 321263 | NT-HD-SST-p-M8x40-MT-F | 18 | M8 | 14.5 | 40 | 22 | 18.8 | 13 | 29 |
| 321273 | NT-HD-SST-p-M10x20-MT-F | 21 | M10 | 18 | 20 | - | 21.8 | 16 | 59 |
| 321283 | NT-HD-SST-p-M10x25-MT-F | 21 | M10 | 18 | 25 | - | 21.8 | 16 | 64 |
| 321293 | NT-HD-SST-p-M10x30-MT-F | 21 | M10 | 18 | 30 | - | 21.8 | 16 | 49 |
| 321303 | NT-HD-SST-p-M10x40-MT-F | 21 | M10 | 18 | 40 | 26 | 21.8 | 16 | 51 |
| 321313 | NT-HD-SST-p-M10x50-MT-F | 21 | M10 | 18 | 50 | 26 | 21.8 | 16 | 54 |
| 321323 | NT-HD-SST-p-M12x25-MT-F | 25 | M12 | 21 | 25 | - | 25.8 | 18 | 79 |
| 321333 | NT-HD-SST-p-M12x30-MT-F | 25 | M12 | 21 | 30 | - | 25.8 | 18 | 84 |
| 321343 | NT-HD-SST-p-M12x40-MT-F | 25 | M12 | 21 | 40 | 30 | 25.8 | 18 | 93 |
| 321353 | NT-HD-SST-p-M12x50-MT-F | 25 | M12 | 21 | 50 | 30 | 25.8 | 18 | 102 |
| 321363 | NT-HD-SST-p-M12x60-MT-F | 25 | M12 | 21 | 60 | 30 | 25.8 | 18 | 111 |
| 321373 | NT-HD-SST-p-M16x30-MT-F | 32 | M16 | 26 | 30 | - | 32.8 | 24 | 157 |
| 321383 | NT-HD-SST-p-M16x40-MT-F | 32 | M16 | 26 | 40 | - | 32.8 | 24 | 173 |
| 321393 | NT-HD-SST-p-M16x50-MT-F | 32 | M16 | 26 | 50 | 38 | 32.8 | 24 | 189 |
| 321403 | NT-HD-SST-p-M16x60-MT-F | 32 | M16 | 26 | 60 | 38 | 32.8 | 24 | 203 |
| 321413 | NT-HD-SST-p-M16x70-MT-F | 32 | M16 | 26 | 70 | 38 | 32.8 | 24 | 216 |
| 321423 | NT-HD-SST-p-M20x40-MT-F | 40 | M20 | 32 | 40 | - | 40.8 | 30 | 296 |
| 321433 | NT-HD-SST-p-M20x60-MT-F | 40 | M20 | 32 | 60 | 46 | 40.8 | 30 | 160 |


NT-HD-SST-p-PL-H



| Code | Description | D | d | L | l | l1 | d1 | s | ⚖ |
|--------|-------------------------|----|-----|------|----|----|------|----|-----|
| 321076 | NT-HD-SST-p-M4x8-PL-H | 11 | M4 | 9.5 | 8 | - | 11.8 | 7 | 5 |
| 321083 | NT-HD-SST-p-M4x10-PL-H | 11 | M4 | 9.5 | 10 | - | 11.8 | 7 | 5 |
| 321086 | NT-HD-SST-p-M4x12-PL-H | 11 | M4 | 9.5 | 12 | - | 11.8 | 7 | 4 |
| 321096 | NT-HD-SST-p-M4x16-PL-H | 11 | M4 | 9.5 | 16 | 14 | 11.8 | 7 | 5 |
| 321146 | NT-HD-SST-p-M5x10-PL-H | 12 | M5 | 10 | 10 | - | 12.8 | 8 | 9 |
| 321156 | NT-HD-SST-p-M5x16-PL-H | 12 | M5 | 10 | 16 | - | 12.8 | 8 | 7 |
| 321166 | NT-HD-SST-p-M5x20-PL-H | 12 | M5 | 10 | 20 | 16 | 12.8 | 8 | 8 |
| 321176 | NT-HD-SST-p-M6x12-PL-H | 14 | M6 | 12 | 12 | - | 14.8 | 10 | 11 |
| 321186 | NT-HD-SST-p-M6x16-PL-H | 14 | M6 | 12 | 16 | - | 14.8 | 10 | 12 |
| 321196 | NT-HD-SST-p-M6x20-PL-H | 14 | M6 | 12 | 20 | - | 14.8 | 10 | 12 |
| 321206 | NT-HD-SST-p-M6x25-PL-H | 14 | M6 | 12 | 25 | - | 14.8 | 10 | 13 |
| 321216 | NT-HD-SST-p-M6x30-PL-H | 14 | M6 | 12 | 30 | 18 | 14.8 | 10 | 14 |
| 321226 | NT-HD-SST-p-M8x16-PL-H | 18 | M8 | 14.5 | 16 | - | 18.8 | 13 | 23 |
| 321236 | NT-HD-SST-p-M8x20-PL-H | 18 | M8 | 14.5 | 20 | - | 18.8 | 13 | 26 |
| 321246 | NT-HD-SST-p-M8x25-PL-H | 18 | M8 | 14.5 | 25 | - | 18.8 | 13 | 25 |
| 321256 | NT-HD-SST-p-M8x30-PL-H | 18 | M8 | 14.5 | 30 | - | 18.8 | 13 | 36 |
| 321266 | NT-HD-SST-p-M8x40-PL-H | 18 | M8 | 14.5 | 40 | 22 | 18.8 | 13 | 30 |
| 321276 | NT-HD-SST-p-M10x20-PL-H | 21 | M10 | 18 | 20 | - | 21.8 | 16 | 46 |
| 321286 | NT-HD-SST-p-M10x25-PL-H | 21 | M10 | 18 | 25 | - | 21.8 | 16 | 43 |
| 321296 | NT-HD-SST-p-M10x30-PL-H | 21 | M10 | 18 | 30 | - | 21.8 | 16 | 50 |
| 321306 | NT-HD-SST-p-M10x40-PL-H | 21 | M10 | 18 | 40 | 26 | 21.8 | 16 | 53 |
| 321316 | NT-HD-SST-p-M10x50-PL-H | 21 | M10 | 18 | 50 | 26 | 21.8 | 16 | 56 |
| 321326 | NT-HD-SST-p-M12x25-PL-H | 25 | M12 | 21 | 25 | - | 25.8 | 18 | 79 |
| 321336 | NT-HD-SST-p-M12x30-PL-H | 25 | M12 | 21 | 30 | - | 25.8 | 18 | 84 |
| 321346 | NT-HD-SST-p-M12x40-PL-H | 25 | M12 | 21 | 40 | 30 | 25.8 | 18 | 93 |
| 321356 | NT-HD-SST-p-M12x50-PL-H | 25 | M12 | 21 | 50 | 30 | 25.8 | 18 | 102 |
| 321366 | NT-HD-SST-p-M12x60-PL-H | 25 | M12 | 21 | 60 | 30 | 25.8 | 18 | 111 |
| 321376 | NT-HD-SST-p-M16x30-PL-H | 32 | M16 | 26 | 30 | - | 32.8 | 24 | 157 |
| 321386 | NT-HD-SST-p-M16x40-PL-H | 32 | M16 | 26 | 40 | - | 32.8 | 24 | 173 |
| 321396 | NT-HD-SST-p-M16x50-PL-H | 32 | M16 | 26 | 50 | 38 | 32.8 | 24 | 189 |
| 321406 | NT-HD-SST-p-M16x60-PL-H | 32 | M16 | 26 | 60 | 38 | 32.8 | 24 | 205 |
| 321416 | NT-HD-SST-p-M16x70-PL-H | 32 | M16 | 26 | 70 | 38 | 32.8 | 24 | 221 |
| 320934 | NT-HD-SST-p-M20x40-PL-H | 40 | M20 | 32 | 40 | - | 40.8 | 30 | 296 |
| 320944 | NT-HD-SST-p-M20x60-PL-H | 40 | M20 | 32 | 60 | 46 | 40.8 | 30 | 346 |



Leveling feet and supports

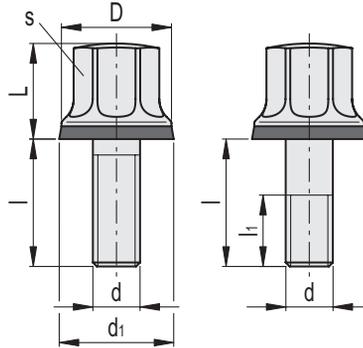

NT-HD-SST-p-PL-E

| Code | Description | D | d | L | l | l1 | d1 | s | ⚖ |
|--------|-------------------------|----|-----|------|----|----|------|----|-----|
| 321077 | NT-HD-SST-p-M4x8-PL-E | 11 | M4 | 9.5 | 8 | - | 11.8 | 7 | 5 |
| 321080 | NT-HD-SST-p-M4x10-PL-E | 11 | M4 | 9.5 | 10 | - | 11.8 | 7 | 5 |
| 321087 | NT-HD-SST-p-M4x12-PL-E | 11 | M4 | 9.5 | 12 | - | 11.8 | 7 | 4 |
| 321097 | NT-HD-SST-p-M4x16-PL-E | 11 | M4 | 9.5 | 16 | 14 | 11.8 | 7 | 5 |
| 321147 | NT-HD-SST-p-M5x10-PL-E | 12 | M5 | 10 | 10 | - | 12.8 | 8 | 13 |
| 321157 | NT-HD-SST-p-M5x16-PL-E | 12 | M5 | 10 | 16 | - | 12.8 | 8 | 11 |
| 321167 | NT-HD-SST-p-M5x20-PL-E | 12 | M5 | 10 | 20 | 16 | 12.8 | 8 | 11 |
| 321177 | NT-HD-SST-p-M6x12-PL-E | 14 | M6 | 12 | 12 | - | 14.8 | 10 | 14 |
| 321187 | NT-HD-SST-p-M6x16-PL-E | 14 | M6 | 12 | 16 | - | 14.8 | 10 | 12 |
| 321197 | NT-HD-SST-p-M6x20-PL-E | 14 | M6 | 12 | 20 | - | 14.8 | 10 | 13 |
| 321207 | NT-HD-SST-p-M6x25-PL-E | 14 | M6 | 12 | 25 | - | 14.8 | 10 | 13 |
| 321217 | NT-HD-SST-p-M6x30-PL-E | 14 | M6 | 12 | 30 | 18 | 14.8 | 10 | 18 |
| 321227 | NT-HD-SST-p-M8x16-PL-E | 18 | M8 | 14.5 | 16 | - | 18.8 | 13 | 24 |
| 321237 | NT-HD-SST-p-M8x20-PL-E | 18 | M8 | 14.5 | 20 | - | 18.8 | 13 | 28 |
| 321247 | NT-HD-SST-p-M8x25-PL-E | 18 | M8 | 14.5 | 25 | - | 18.8 | 13 | 28 |
| 321257 | NT-HD-SST-p-M8x30-PL-E | 18 | M8 | 14.5 | 30 | - | 18.8 | 13 | 30 |
| 321267 | NT-HD-SST-p-M8x40-PL-E | 18 | M8 | 14.5 | 40 | 22 | 18.8 | 13 | 33 |
| 321277 | NT-HD-SST-p-M10x20-PL-E | 21 | M10 | 18 | 20 | - | 21.8 | 16 | 49 |
| 321287 | NT-HD-SST-p-M10x25-PL-E | 21 | M10 | 18 | 25 | - | 21.8 | 16 | 52 |
| 321297 | NT-HD-SST-p-M10x30-PL-E | 21 | M10 | 18 | 30 | - | 21.8 | 16 | 54 |
| 321307 | NT-HD-SST-p-M10x40-PL-E | 21 | M10 | 18 | 40 | 26 | 21.8 | 16 | 59 |
| 321317 | NT-HD-SST-p-M10x50-PL-E | 21 | M10 | 18 | 50 | 26 | 21.8 | 16 | 64 |
| 321327 | NT-HD-SST-p-M12x25-PL-E | 25 | M12 | 21 | 25 | - | 25.8 | 18 | 79 |
| 321337 | NT-HD-SST-p-M12x30-PL-E | 25 | M12 | 21 | 30 | - | 25.8 | 18 | 84 |
| 321347 | NT-HD-SST-p-M12x40-PL-E | 25 | M12 | 21 | 40 | 30 | 25.8 | 18 | 93 |
| 321357 | NT-HD-SST-p-M12x50-PL-E | 25 | M12 | 21 | 50 | 30 | 25.8 | 18 | 102 |
| 321367 | NT-HD-SST-p-M12x60-PL-E | 25 | M12 | 21 | 60 | 30 | 25.8 | 18 | 111 |
| 321377 | NT-HD-SST-p-M16x30-PL-E | 32 | M16 | 26 | 30 | - | 32.8 | 24 | 157 |
| 321387 | NT-HD-SST-p-M16x40-PL-E | 32 | M16 | 26 | 40 | - | 32.8 | 24 | 173 |
| 321397 | NT-HD-SST-p-M16x50-PL-E | 32 | M16 | 26 | 50 | 38 | 32.8 | 24 | 189 |
| 321407 | NT-HD-SST-p-M16x60-PL-E | 32 | M16 | 26 | 60 | 38 | 32.8 | 24 | 205 |
| 321417 | NT-HD-SST-p-M16x70-PL-E | 32 | M16 | 26 | 70 | 38 | 32.8 | 24 | 221 |
| 320933 | NT-HD-SST-p-M20x40-PL-E | 40 | M20 | 32 | 40 | 46 | 40.8 | 30 | 296 |
| 320943 | NT-HD-SST-p-M20x60-PL-E | 40 | M20 | 32 | 60 | 46 | 40.8 | 30 | 346 |

NT-HD-SST-PL-F

| Code | Description | D | d | L | l | l1 | d1 | s | ⚖ |
|--------|-------------------------|----|-----|------|----|----|------|----|-----|
| 321075 | NT-HD-SST-p-M4x8-PL-F | 11 | M4 | 9.5 | 8 | - | 11.8 | 7 | 5 |
| 321085 | NT-HD-SST-p-M4x10-PL-F | 11 | M4 | 9.5 | 10 | - | 11.8 | 7 | 6 |
| 321089 | NT-HD-SST-p-M4x12-PL-F | 11 | M4 | 9.5 | 12 | - | 11.8 | 7 | 7 |
| 321098 | NT-HD-SST-p-M4x16-PL-F | 11 | M4 | 9.5 | 16 | 14 | 11.8 | 7 | 8 |
| 321148 | NT-HD-SST-p-M5x10-PL-F | 12 | M5 | 10 | 10 | - | 12.8 | 8 | 10 |
| 321158 | NT-HD-SST-p-M5x16-PL-F | 12 | M5 | 10 | 16 | - | 12.8 | 8 | 11 |
| 321168 | NT-HD-SST-p-M5x20-PL-F | 12 | M5 | 10 | 20 | 16 | 12.8 | 8 | 12 |
| 321178 | NT-HD-SST-p-M6x12-PL-F | 14 | M6 | 12 | 12 | - | 14.8 | 10 | 14 |
| 321188 | NT-HD-SST-p-M6x16-PL-F | 14 | M6 | 12 | 16 | - | 14.8 | 10 | 15 |
| 321198 | NT-HD-SST-p-M6x20-PL-F | 14 | M6 | 12 | 20 | - | 14.8 | 10 | 16 |
| 321208 | NT-HD-SST-p-M6x25-PL-F | 14 | M6 | 12 | 25 | - | 14.8 | 10 | 17 |
| 321218 | NT-HD-SST-p-M6x30-PL-F | 14 | M6 | 12 | 30 | 18 | 14.8 | 10 | 18 |
| 321228 | NT-HD-SST-p-M8x16-PL-F | 18 | M8 | 14.5 | 16 | - | 18.8 | 13 | 33 |
| 321238 | NT-HD-SST-p-M8x20-PL-F | 18 | M8 | 14.5 | 20 | - | 18.8 | 13 | 24 |
| 321248 | NT-HD-SST-p-M8x25-PL-F | 18 | M8 | 14.5 | 25 | - | 18.8 | 13 | 26 |
| 321258 | NT-HD-SST-p-M8x30-PL-F | 18 | M8 | 14.5 | 30 | - | 18.8 | 13 | 27 |
| 321268 | NT-HD-SST-p-M8x40-PL-F | 18 | M8 | 14.5 | 40 | 22 | 18.8 | 13 | 29 |
| 321278 | NT-HD-SST-p-M10x20-PL-F | 21 | M10 | 18 | 20 | - | 21.8 | 16 | 59 |
| 321288 | NT-HD-SST-p-M10x25-PL-F | 21 | M10 | 18 | 25 | - | 21.8 | 16 | 64 |
| 321298 | NT-HD-SST-p-M10x30-PL-F | 21 | M10 | 18 | 30 | - | 21.8 | 16 | 49 |
| 321308 | NT-HD-SST-p-M10x40-PL-F | 21 | M10 | 18 | 40 | 26 | 21.8 | 16 | 51 |
| 321318 | NT-HD-SST-p-M10x50-PL-F | 21 | M10 | 18 | 50 | 26 | 21.8 | 16 | 54 |
| 321328 | NT-HD-SST-p-M12x25-PL-F | 25 | M12 | 21 | 25 | - | 25.8 | 18 | 79 |
| 321338 | NT-HD-SST-p-M12x30-PL-F | 25 | M12 | 21 | 30 | - | 25.8 | 18 | 84 |
| 321348 | NT-HD-SST-p-M12x40-PL-F | 25 | M12 | 21 | 40 | 30 | 25.8 | 18 | 93 |
| 321358 | NT-HD-SST-p-M12x50-PL-F | 25 | M12 | 21 | 50 | 30 | 25.8 | 18 | 102 |
| 321368 | NT-HD-SST-p-M12x60-PL-F | 25 | M12 | 21 | 60 | 30 | 25.8 | 18 | 111 |
| 321378 | NT-HD-SST-p-M16x30-PL-F | 32 | M16 | 26 | 30 | - | 32.8 | 24 | 157 |
| 321388 | NT-HD-SST-p-M16x40-PL-F | 32 | M16 | 26 | 40 | - | 32.8 | 24 | 173 |
| 321398 | NT-HD-SST-p-M16x50-PL-F | 32 | M16 | 26 | 50 | 38 | 32.8 | 24 | 189 |
| 321408 | NT-HD-SST-p-M16x60-PL-F | 32 | M16 | 26 | 60 | 38 | 32.8 | 24 | 203 |
| 321418 | NT-HD-SST-p-M16x70-PL-F | 32 | M16 | 26 | 70 | 38 | 32.8 | 24 | 216 |
| 321428 | NT-HD-SST-p-M20x40-PL-F | 40 | M20 | 32 | 40 | 46 | 40.8 | 30 | 296 |
| 321438 | NT-HD-SST-p-M20x60-PL-F | 40 | M20 | 32 | 60 | 46 | 40.8 | 30 | 160 |

Levelling feet and supports