


## LED A60 E27 24V AC/DC 7W (60W) 800lm 827

Article number 80100040597

BAI LED GLS A60 E27 7W 2700K Opal 800lm (60W) Low voltage 24V AC/DC 170° 60x108mm LED-lamp

This low-voltage series is especially suitable for rooms where one is not on the usual high-voltage network and where power is supplied by battery or generator. Think of boats, basements, garages, storage areas and rural and isolated areas. Suitable for both AC and DC voltage. Bulb made of plastic.

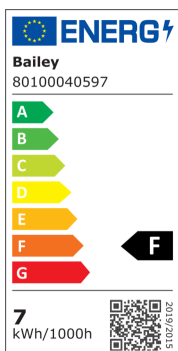

### General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	80100040597
Brand	Bailey
Productseries	Low voltage LED bulb
Product type	A60

## ETIM specifications

Nominal voltage [V]	24 - 24
Nominal current [mA]	486 - 486
Power factor	0.6
Lamp power [W]	7 - 7
Voltage type	AC/DC
Luminous flux [lm]	800 - 800
Rated luminous flux according to IEC 62612 [lm]	800
Lamp efficacy [lm/W]	114
Colour rendering index CRI	80-89
Lamp shape	Pear-shape
Filament lamp	No
Type of glass/cover	Opal
Colour of light according to EN 12464-1	Warm white <3300 K
Socket	E27
Colour	White
Colour temperature [K]	2700 - 2700
Colour housing	White
Beam angle [°]	170 - 170
Colour consistency (McAdam ellipse)	Other
Dimmable	No
Diameter [mm]	60
Length [mm]	108
Degree of protection (IP)	IP20
Energy Efficiency Index (EEI)	0.13
Lamp designation	A-type
Energy efficiency class	F
Min. number of switching cycles	10000
Weighted energy consumption in 1000 hours [kWh]	7
Average nominal lifespan [h]	20000
Remote operation possible	No
With remote control	No
Photobiological safety according to EN 62471	Other
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No

### Alternative articles



143074

LED A60 E27 12-60V  
AC/DC 10W (60W)  
810lm 830



143115

LED A60 E27 12-60V  
AC/DC 7W (45W)  
550lm 830



145609

LED FIL A60 E27  
12V-24V AC/DC 6W  
690lm (53W) 827 Clear