


Self-Lube[®] bearing inserts complete with snap ring 1100CG Series

1100CG
With parallel outside diameter and integral set screw lock

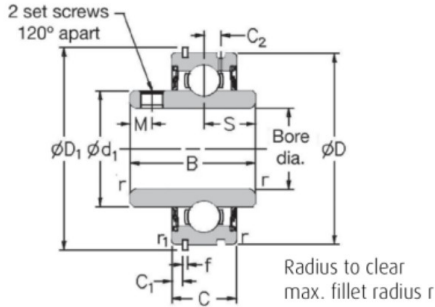

Shaft diameter mm inches	RHP designation 1100CG Series	Dimensions (mm)												ISO Load ratings		Rec. max. speed rev/min	Mass (approx.) kg
		D	D1	C	C1	C2	B	s	d1	f	M	r	r1	dynamic Cr newtons	static Cor newtons		
20	1120-20CG	47.000	52.68	15.88	2.39	4.17	31.00	12.73	28.30	1.12	5.00	1.00	0.50	12800	6650	6700	0.23
3/4	1120-3/4CG																
25	1125-25CG	52.000	57.81	19.05	2.39	4.39	34.10	14.33	34.00	1.12	5.00	1.00	0.50	14000	7880	6250	0.31
7/8	1125-7/8CG																
1 1/16	1125-1 1/16CG																
1	1125-1CG																
30	1130-30CG	62.000	67.69	22.22	3.18	5.10	38.10	15.93	40.30	1.70	5.00	1.00	0.50	19500	11300	5300	0.42
1 1/8	1130-1 1/8CG																
1 3/16	1130-1 3/16CG																
35	1135-35CG	72.000	78.51	23.81	3.18	5.61	42.90	17.53	46.90	1.70	6.50	1.00	1.00	25700	15300	4500	0.61
1 1/4	1135-1 1/4CG																
1 3/8	1135-1 3/8CG																
1 7/8	1135-1 7/8CG																
40	1140-40CG	80.000	86.51	27.78	3.18	6.22	49.20	19.03	52.40	1.70	8.00	1.00	1.00	32500	19900	4000	0.91
1 1/2	1140-1 1/2CG																
45	1145-45CG	85.000	91.51	27.78	3.18	6.52	49.20	19.04	57.40	1.70	8.00	1.00	1.00	32500	20500	3700	1.05
1 5/8	1145-1 5/8CG																
1 11/16	1145-1 11/16CG																
1 3/4	1145-1 3/4CG																
1 7/8	1150-1 7/8CG	90.000	96.49	28.58	3.18	6.72	51.59	19.10	62.40	2.46	10.00	1.00	1.00	35000	23200	3400	1.10
1 15/16	1150-1 15/16CG																
55	1155-55CG	100.00	106.50	30.16	3.18	7.43	55.60	22.20	68.90	2.46	10.00	1.00	1.00	43500	29200	3100	1.50
2	1155-2CG																
2 3/16	1155-2 3/16CG																

Please check availability