

## 特点

- 高功率 12V 碱性电池
- 高电压响应
- 低自放电率
- 易于使用
- 广泛的工作温度范围
- 存储和工作寿命长

# RS Pro 12V A27 电池

RS 号: 801-0718



RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与领先品牌相当的质量、而无需支付高昂的价格。

## 商品描述属性 1

RS PRO 碱性 A27 12V 电池此电池是非标准尺寸的 A27 电池、设计用于可靠的专业应用、如遥控钥匙、车库门、打火机、摄影设备等具有宽温度工作范围和长存储寿命、是需要此特殊 A27 电池尺寸的任何家庭或专业应用的理想选择。

## 一般规格

品牌范围	RS PRO
iec 名称	iec 60086-1 和 iec 60086-2
Terminal	标准
存储寿命	24Months
应用	远程控制、摄影设备、存储器备份、壁挂时钟、汽车电子产品、专业电子产品

## 电气规格


尺寸	A27
化学	碱性
额定电压	12V
容量	25mAh

## 机械规格

尺寸	8mm x 28.2mm
重量	4.3 ±0.2g

## 认证

合规性 / 认证	2011/65/eu and 2015/863,
----------	--------------------------

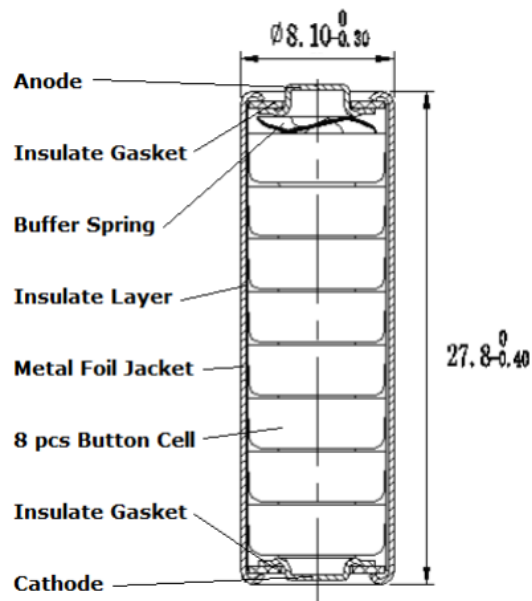

Discharges					
Test Condition			Average duration at 20°C <sup>1)</sup>		
Load	Daily Period	End Voltage	Initial	After 12 months storage <sup>2)</sup>	After 24 months storage <sup>2)</sup>
20 kΩ	24 h/d	6.0 V	55.0 h	48.0 h	40.0 h
1 kΩ	24 h/d	6.0 V	100 min	85 min	70 min

Description	AQL	
Battery dimensions	0.65%	
Appearance	1.00%	
Off load voltage	0.65%	
On load voltage	1.00%	
Service output	Note 1	
Leakage	6.1	1.00% (Note 2)
	6.2	Note 3
	6.3	Note 4

Note 1: Acceptance/rejection in accordance with IEC publication (1993) 86-1 Sub-clause 8.8

Note 2: Leakage on arrival at warehouse is within two months after shipping.

Note 3: Sample size: n = 20; Judgement: Ac = 1, Re = 2.

Note 4: Sample size: n = 20; Judgement: Ac = 1, Re = 2.