



DATASHEET



SUR5SL

230V IP20 40W LED Dual Mount Slim Line Luminaire

www.mlaccessories.co.uk

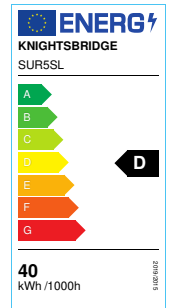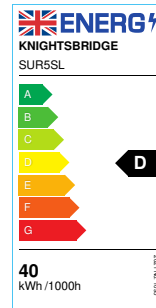

MLA PART CODE	SUR5SL
DESCRIPTION	230V IP20 40W LED Dual Mount Slim Line Luminaire
NET WEIGHT (KG)	2.75
FINISH	White
DIFFUSER	Opal
DIMENSIONS (MM)	Length - 1500 Width - 145 Projection - 45
CONSTRUCTION	Construction - Pressed steel Construction 2 - & polypropylene
CLASS	I
IP RATING	IP20
WATTAGE (W)	40
LAMP TECHNOLOGY	SMD LED
LAMP INCLUDED	Yes
LUMENS (LM)	3600
LUMENS LIGHT SOURCE ONLY (LM)	5600
LUMEN TOLERANCE	5%
EFFICACY (LM/W)	140
CIRCUIT WATTAGE (W)	39.95
CCT	4000K
LIGHT COLOUR	Cool White
CRI	>80
SDCM	<6
RUNNING CURRENT (A)	0.178
DISPLACEMENT FACTOR	>0.9
SVM	0
PST-LM	0
BEAM ANGLE (DEGREES)	115
LIFE SPAN (HRS)	50,000

L70B50 LIFESPAN (HRS)	50,000
DIMMABLE	No
OPERATING TEMPERATURE	25°C
INPUT VOLTAGE	230V 50Hz
CABLE ENTRY (MM)	20
CABLE GLAND INCLUDED	Blind grommet
DRIVER	DRIVER TYPE - Constant Current MAX. OUTPUT - 42W OUTPUT VOLTAGE - 30-43V OUTPUT CURRENT - 960mA POWER FACTOR - 0.95 EFFICIENCY FULL LOAD - 95.0 ISOLATION - SELV AMBIENT TEMPERATURE (Ta) - -20~50°C CASE TEMPERATURE (Tc) - 75°C
WARRANTY	5year(s)
MANUFACTURED IN ACCORDANCE WITH	BS 60598
ORIGIN OF MANUFACTURE	China
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes
EAN	5056270864670

Date Created: 03/06/2025 13:49

