

Multi-LEDs Pygmy



Features

- Extremely energy saving with low power consumption
- Perfect replacing incandescent Pygmy lamp
- Long average life 25000 hours
- Operation temperature -20°C to 60°C
- Suitable for Refrigerator light, Indication light and night light
- Low thermal output with no IR and harmful UV
- No mercury and hazardous substances

Materials / Chips

High efficiency SMD 5050

Standards

CE, LVD, EMC, RoHS

Guarantee



2 years from date of purchase



T25



T28

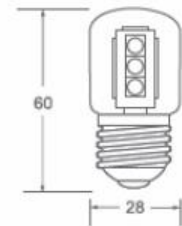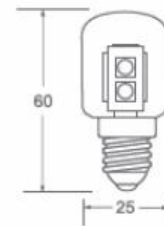



 1.1W Replacing most popular
 1.4W ~ 15W-25W incandescent
 1.6W Pygmy lamps.



Part No.	Voltage	Power Consumption	Lumens	Colour Temperature	Base	Size
820-8823	220-240 V	1.6 W	150	3000 K	B22	T28
820-8827	220-240 V	1.6 W	150	3000 K	E27	T28
820-8836	220-240 V	1.4 W	130	3001 K	E14	T25

