



Brand of NTN corporation

Technical data

UCPE211-32

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC211-32G2, PE211

VISUAL (S)

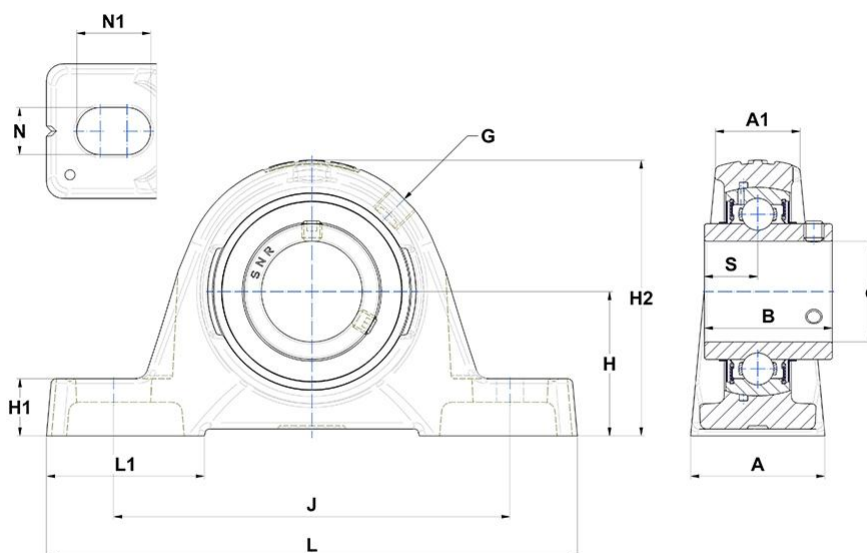

PRODUCT DEFINITION

Brand	SNR
A - Housing width	60 mm
A1 - Housing top width	35 mm
B - Width of Inner Ring	55,6 mm
d - Shaft diameter	50,8 mm
G - Grease fitting	R1/8"



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

H - Distance mounting base to centerline spheric. seating diam.	63,5 mm
H1 - Housing foot height	22,5 mm
H2 - Housing height	124,5 mm
J - Mounting holes distance	176 mm
L - Housing length	222 mm
L1 - Housing foot length	68 mm
N - Mounting hole dimension	18 mm
N1 - Mounting hole length	30 mm
S - Distance front side/bearing centre	22,2 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	43550000 mN
C0 - Static load rating	29200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	3,57 kg
Recommended tightening torque for set screw	16.8 N-m

