



ENGLISH


Datasheet

Stock No: 123-4269

RS Pro

Product Description: Common mode choke 2x 2.70mH / 4 Amps

Schematic :



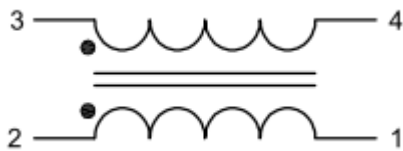


Electrical Specifications@25°C

- 1) $L_p : (2-1) = (3-4) = 2.70\text{mH} \pm 30\% @ 10\text{KHz} / 0.1\text{mA}$
- 2) $\text{DCR} : (2-1) = (3-4) = 60 \text{ m}\Omega \text{ (Typ.)}$
- 3) Turns Ratio $(2-1) : (3-4) = 1 : 1$
- 4) Rated Current = 4.0 Amps
- 5) Rated Voltage = 250 V / (50/60 Hz)
- 6) H.V. Test :
Wdg - Wdg = 1.50 KVrms / 50Hz / 2sec



Mechanical Specification :

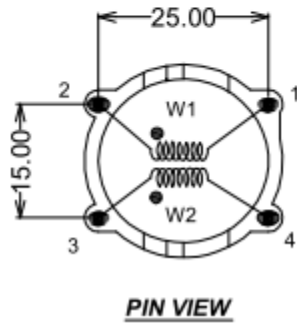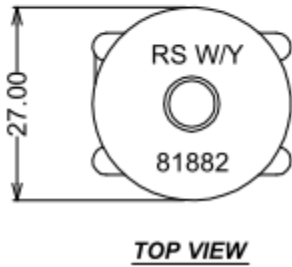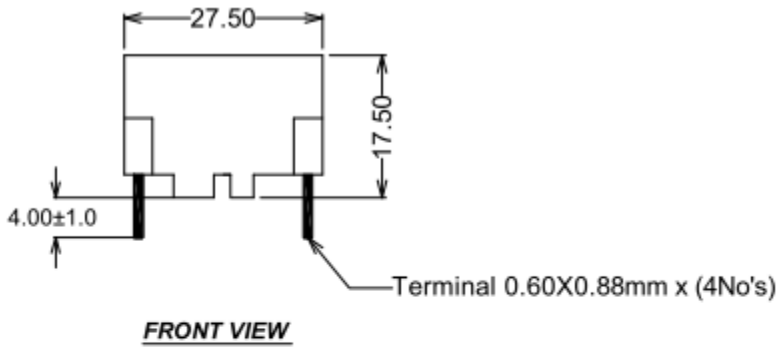

Case accordance with UL94-V0

Unit : mm	Dimension tolerance : ±0.25mm (Unless specified)	Pin pitch tolerance : ±0.20mm
-----------	--	-------------------------------

