
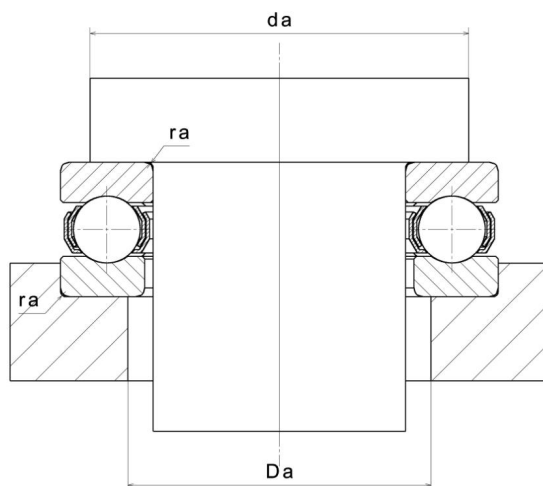


Technical data

51117

One direction thrust ball bearings

VISUAL (S)

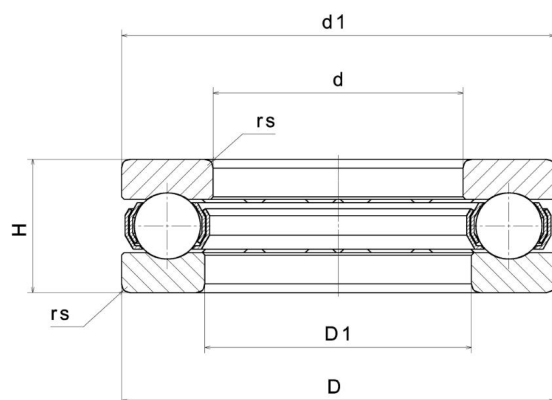

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	85 mm
D - External diameter	110 mm
T - Thrust bearing height	19 mm
rs - Min fillet radius	1 mm
Mass	0,444 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	46000000 mN
C0a - Static axial load rating	150000000 mN
Cua - Limit axial load rating	6800000 mN
N lim - Oil lubrication limit speed	18000 °/s
N lim - Grease lubrication limit speed	12600 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	95 mm
da min - Min shoulder diameter IR	100 mm

