


Product Datasheet

Rechargeable

eneloop pro AAA



BK-4HCDE

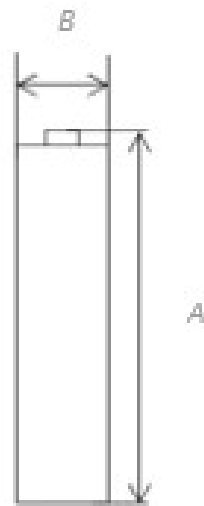


IEC Dimensions (mm)		
Dimension	Maximum	Minimum
A	44,5	
B	10,5	


Name	BK-4HCDE
Size	AAA
Type	NiMH rechargeable
Nominal Voltage	1.2 V
Made in	Japan
Average weight	13 g
Capacity (minimum)	930 mAh
Ambient temp. charge	0°C - 40°C
Ambient temp. discharge	-20°C - 50°C
Internal impedance (after discharge to E.V.=1.0V)	Approx. 45 mΩ (at 1000Hz)

Typical characteristics

Charge

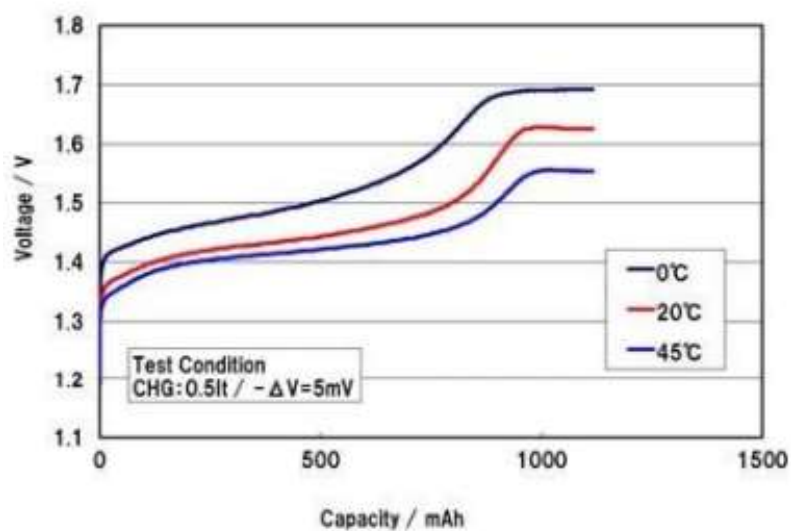

Discharge

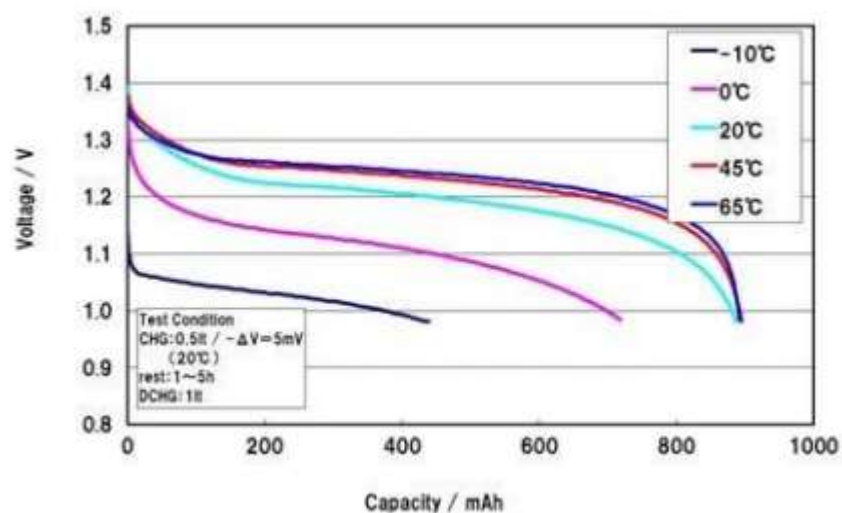

Copyright© Advance Power Solutions NV 2022 — All rights reserved. The information contained herein is believed to be correct. However no warranty is made, either expressed or implied regarding the accuracy or the results to be obtained from the use of such information. Test results are according to IEC conditions. Capacities of batteries are depending on drain, temperature and cut-off voltage. Data are subject to change without prior notification.
October 2022.