
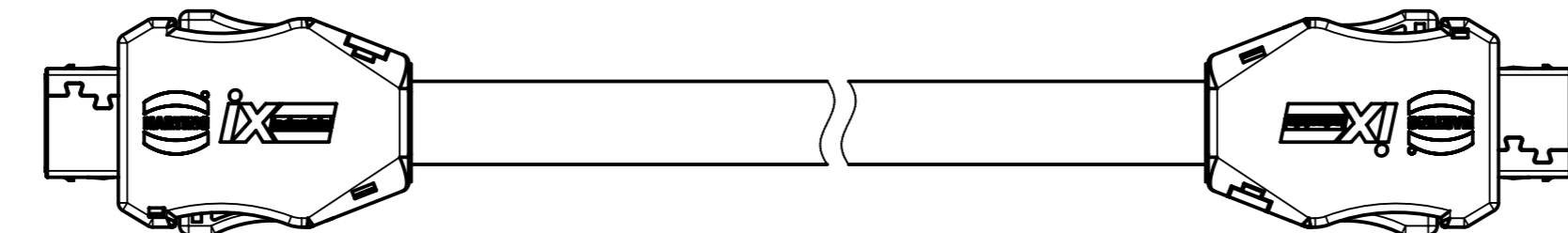


Connector Location A





Connector Location B

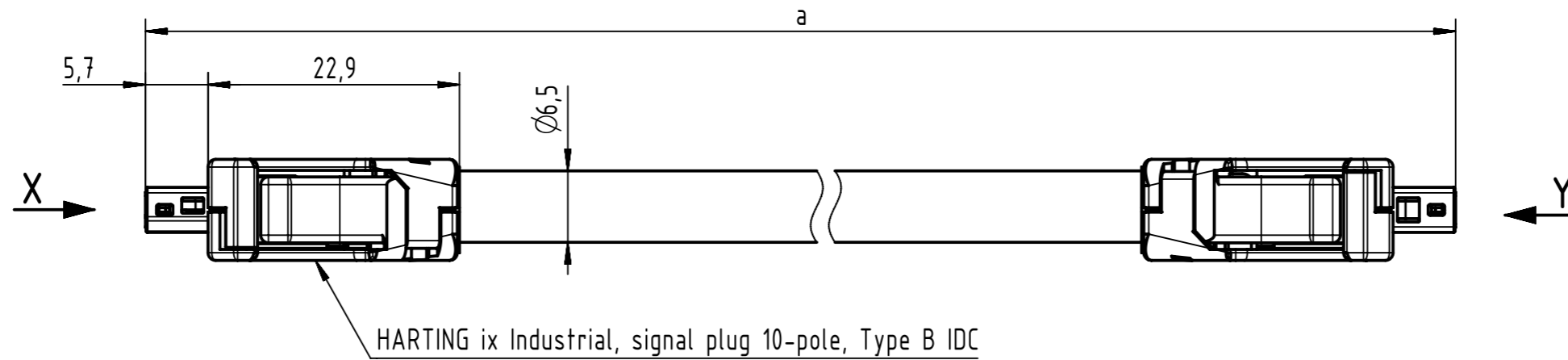

X

Loading-Plan  
acc. to DIN 47100

Y

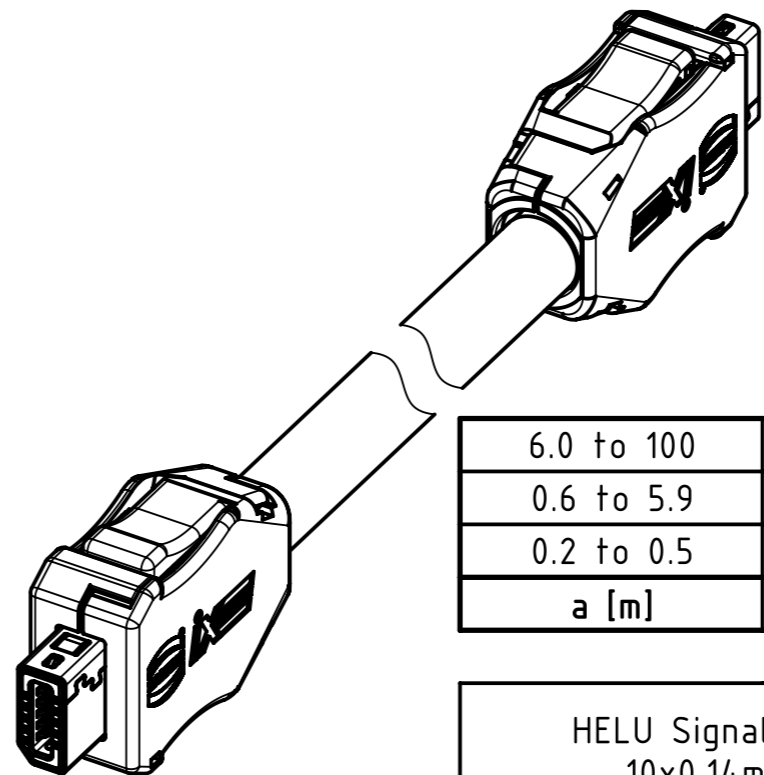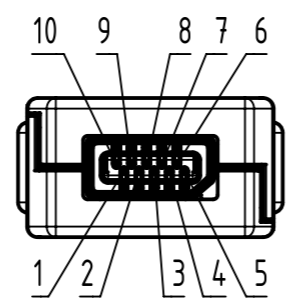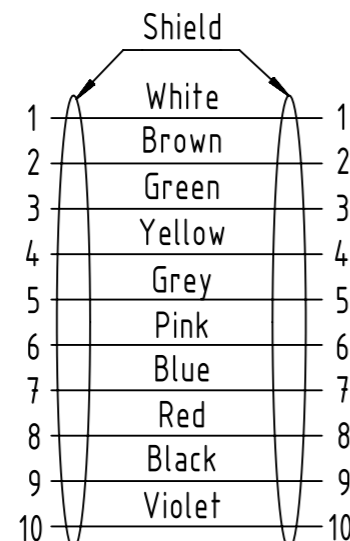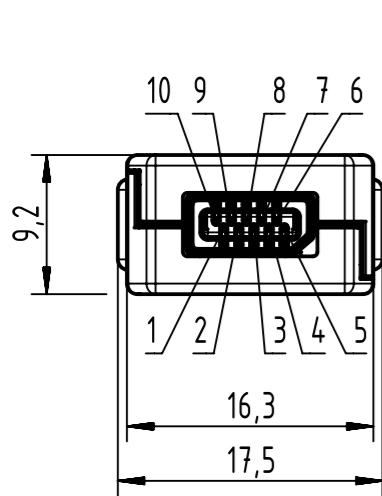

6.0 to 100	±1%
0.6 to 5.9	+0.04
0.2 to 0.5	+0.02
<b>a [m]</b>	<b>Tolerance</b>

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.5	XXX=005
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
<b>Step</b>	<b>a [m]</b>	<b>XXX</b>

HELU Signal PUR cable  
10x0.14mm<sup>2</sup>, grey

**Type of cable**

33481111A21XXX

**Part no.**

- Protection level: IP20
- Temperature range: -40°C...+80°C
- Contact material: copper alloy
- Contact area: Gold 0.2µm min.

	All rights reserved		Created by STOCHECIC		Inspected by COSTEA		Standardisation AVRAM		Date 2018-01-12		State Final Release	
	Department HCS - RO		Title ix Industrial Type B PUR cable assembly		Doc-Key / ECM-Nr. 100758988/UGD/000/A 500000129886		Rev. A		Page 1/1			
HARTING Customised Solutions		Type TB		Number 33481111A21XXX								
D-32339 Espelkamp												