

AN05 to 40, Silencer, Compact Resin Type, Male Thread AN10-01

Datasheet

General series information

- Space saving.
- Noise reduction improved: 30 dB(A).
- M thread, R (NPT) thread type.






Silencer

Standard specifications

Body Size	10
Thread Type	Rc or Metric
Thread Connection Port Size	01 (1/8)
Pressure medium	Compressed Air
Maximum ambient temperature	60 °C
Maximum ambient temperature with magnet	5 °C
Noise reduction	30 dB
Effective Area	10 mm ²
Weight	0.001 Kg

Dimensions

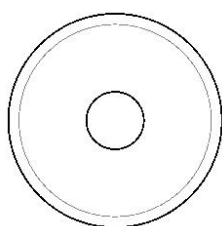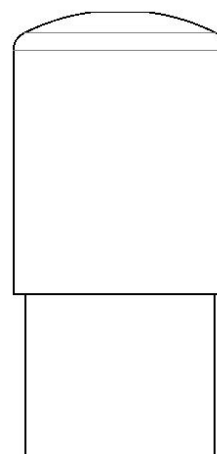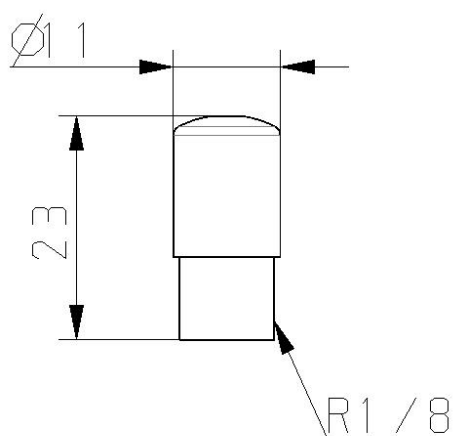

Additional information

Catalogue

[AN-A_EU.pdf](#)