




Tests / approvals		
EMC	EN 60947-5-2	
MTTF [years]		653



Fibre-optic amplifier

OUF-HPKG

Mechanical data		
Weight	[g]	152
Housing		rectangular
Dimensions	[mm]	28 x 16 x 56
Materials		PPO modified
Lens alignment		side lens
Displays / operating elements		
Display	switching status	1 x LED, yellow
Accessories		
Items supplied	Angle bracket: 1, E20211	
	screwdrivers	
Remarks		
Remarks	light-on mode corresponds to the NC output function for through-beam fibre optics	
	corresponds to the NO output function for diffuse-reflection fibre optics	
Pack quantity	1 pcs.	
Electrical connection		
Cable: 2 m, PVC; 3 x 0.34 mm²		
Connection		

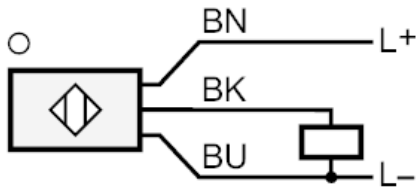

BN = Core colours : brown
BU = blue
BK = black



Diagrams and graphs

excess gain graph

