



SIVACON, door, left, IP55, H: 2200 mm, W: 400 mm, RAL 7035, protection class 1

Model	
product brand name	SIVACON
product designation	Door
design of the product	Closed
design of the surface	Powder-coated
design of the product EMC version	No
Protection class	
protection class IP	IP55
operating resource protection class	safety class 1
Appearance	
RAL color number	7035
color	light grey
Product details	
product component	
• ventilation	No
• viewing door	No
• door for disconnecter lock	No
Mechanical Design	
height	2 200 mm
width	400 mm
opening direction of the door	left
net weight	13 kg
material	steel
Approvals Certificates	
General Product Approval	
Test Certificates	
other	
 EG-Konf.  UKCA  EAC Special Test Certificate Confirmation Miscellaneous	
other	Environment
Miscellaneous  Siemens EcoTech Environmental Confirmations	
Further information	
Information on the packaging	

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1240-2UT15-0BA2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1240-2UT15-0BA2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1240-2UT15-0BA2

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

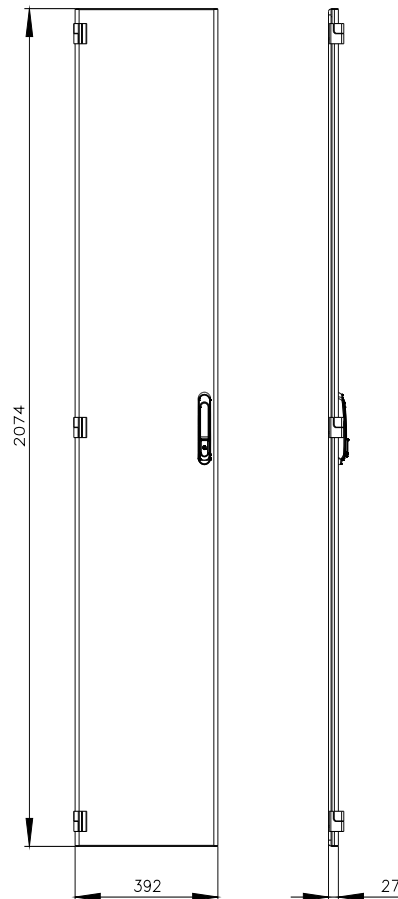

last modified:

4/13/2025 

