



TE Internal #: 1745013-1

TE Internal Description: 12 POS.RECEPTACLE CONNECTOR FOR 070 MULT

MULTILOCK, CONNECTOR HOUSING

[View on TE.com >](#)



All MULTILOCK, CONNECTOR HOUSING (145)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts



TE Part # 1745014-1
12 POS.RECEPTACLE CONNECTOR FOR 070 MULT



TE Part # CAT-M9194-T273
MULTILOCK, RECEPTACLE AND TAB




TE Part # 1745014-1
12 POS.RECEPTACLE CONNECTOR FOR 070 MULT

Customers Also Bought




TE Part #1-1418479-1
8POS,AMP MCP1.5K,REC. HSG,CODA

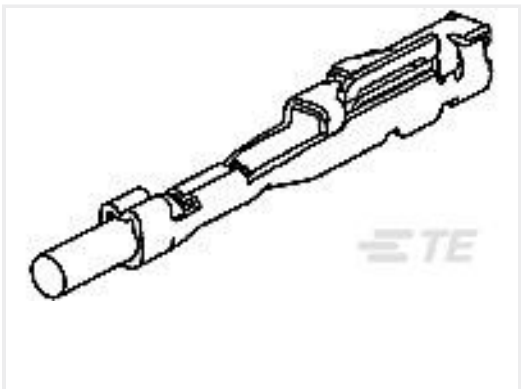

TE Part #1123343-1
025 REC CONTACT



TE Part #1-87160-0
09 MODI HDR SRST .156CL

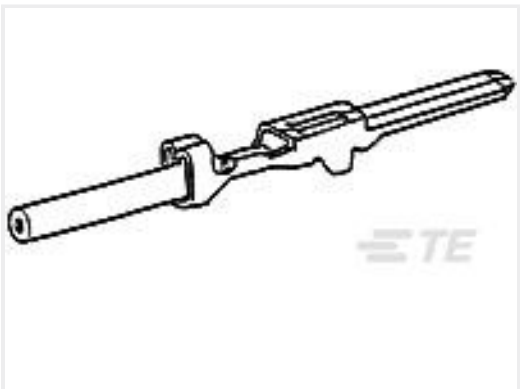


TE Part #345212-1
070 SERIES TAB




TE Part #7-1462037-0
IM47GR=IM RELAY 200mW 24V BIS



 TE Part #1-1418479-1
8POS,AMP MCP1.5K,REC. HSG,CODA



TE Part #1604905-2
KIT,BACKSHELL,2 POS,PLUG

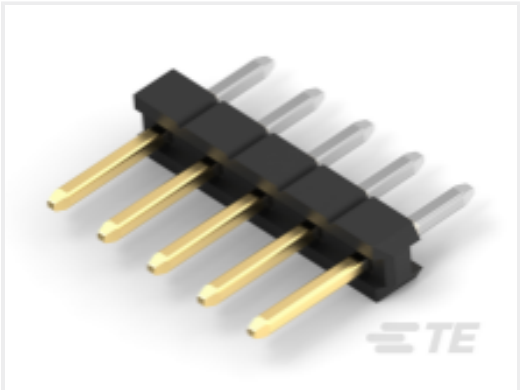

TE Part #2355179-6
6P,2MM,BRK HDR,SRVT,2.8,0.38AU,TB W/CAP



TE Part #1060-16-1222
PIN, SF, SIZE 16, 12-16, NI/SN



TE Part #1745044-2
24 POS MALE CONN.SEALED FOR TAB1.5/2.8

Documents

Product Drawings
12 POS.RECEPTACLE CONNECTOR FOR 070 MULT

English

CAD Files
3D PDF
3D



Customer View Model

[ENG_CVM_CVM_1745013-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1745013-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1745013-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[MULTILOCK Connector System](#)

English

Product Specifications

[Product Specification](#)

English

Instruction Sheets

[6+6 POSITION REC. CONNECTOR 070 MULTILOCK CRIMP SYSTEM - 3.5mm PITCH](#)

English

[Instruction Sheet \(non U.S.\)](#)

English