




LED FIL T16X90 E14 0.6W 35lm 825 Clear

Article number: 146583

BAI LED Filament Tube T16 E14 0.6W 2500K Clear 35lm (4W) 230V-240V 320° 16x90mm LED-lamp

LED filament lamps can be seen as the modern sustainable version of the old incandescent lamp. The so-called filaments replace the traditional filament, making the lamps many times more energy-efficient and last much longer. Due to the warm 2500K light color, the lamps are also eye-friendly.

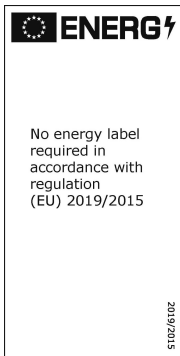

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL T16X90 E14 0.6W 35lm 825 Clear
Brand	Bailey
Productseries	LED Filament tube
Producttype	T16x90

ETIM specifications

Socket	E14
Luminous flux [lm]	35 - 35
Nominal voltage [V]	220 - 240
Lamp power [W]	0.6 - 0.6
Colour temperature [K]	2500 - 2500
Diameter [mm]	16
Length [mm]	90
Dimmable	Yes
Lamp shape	Tube, single-ended
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	35
Power factor	0.9
Lamp efficacy [lm/W]	60
Nominal current [mA]	2 - 2
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	10000
Weighted energy consumption in 1000 hours [kWh]	1
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No
Dimming Bluetooth	No

Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	Not required
With twilight switch	No
Material of light bulb	Glass
