



Brand of NTN corporation

Technical data

USPAE202

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US.202.G2, PAE203

VISUAL (S)

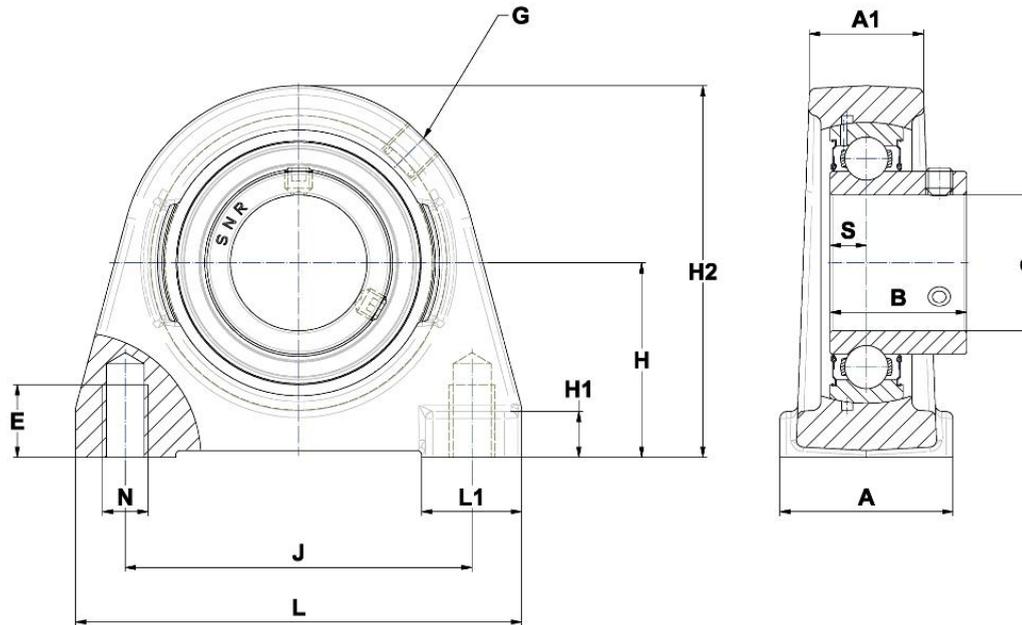

PRODUCT DEFINITION

Brand	SNR
A - Housing width	30 mm
A1 - Housing top width	18 mm
B - Width of Inner Ring	22 mm
d - Shaft diameter	15 mm
E - Mounting hole thread depth	10 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

G - Grease fitting	M6x1
H - Distance mounting base to centerline spheric. seating diam.	30,2 mm
H1 - Housing foot height	9 mm
H2 - Housing height	57 mm
J - Mounting holes distance	47 mm
L - Housing length	63 mm
L1 - Housing foot length	17,5 mm
N - Mounting hole dimension	M8
S - Distance front side/bearing centre	6 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	9550000 mN
C0 - Static load rating	4780000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,38 kg
Recommended tightening torque for set screw	3.5 N-m

