


STARLIGHT: Rechargeable battery-powered industrial Torch- Light

Superior quality halogen technology.
Reflector diameter of approx. 100 mm.
Zoom focussing.
All units complete with wall bracket and charger with European licenced plug-
type transformer.
CE labeled.

Description	STARLIGHT 200	STARLIGHT 400
		
Batteries	4 NiCd 1600 mAh	5 NiCd 1600 mAh
Bulb	4 Watt Halogen	10 Watt Halogen /
Runtime approx.	120 min.	60 / 200 min.
Illumination range approx.	800 m.	1000 m.
Flasher electronics	-	yes
Mains failure detection/ emergency light	-	yes
Carrying strap	-	yes
Color filter-disks red+green	-	yes
Weight	660 gramm	770 gramm

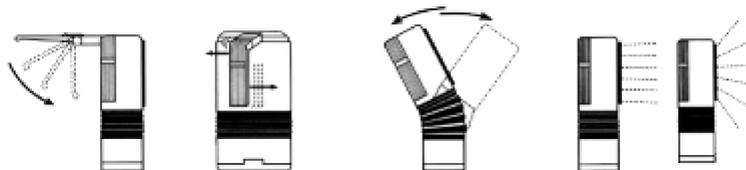

Optional: car charger

Optionals: