


Datasheet

RS 2.5 mm, 5 mm Pitch 21 Way 2 Row Right Angle Male DIN 41617 Connector, Solder Termination, 6A

RS Stock number [290-4768](#)

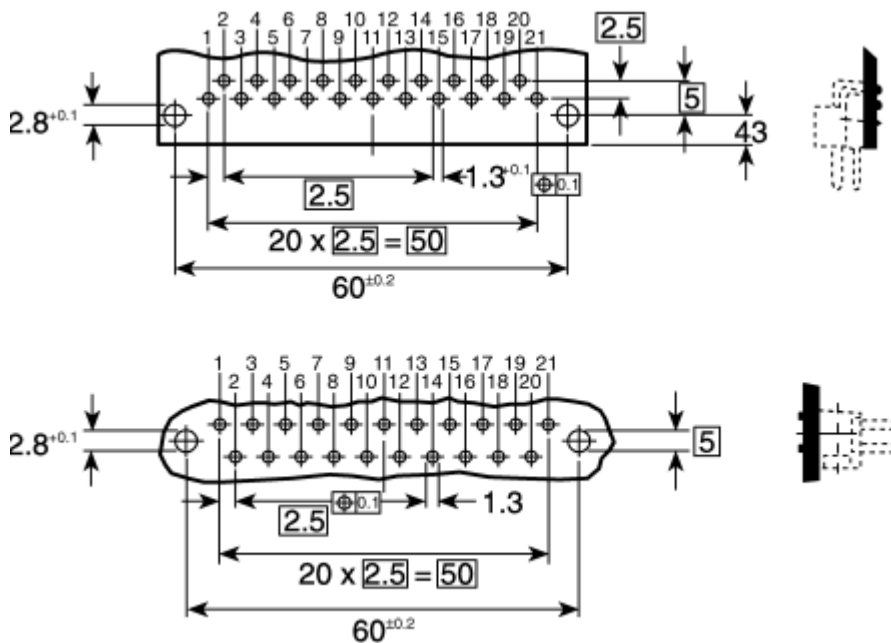

Specifications

- Body Orientation: Right Angle
- Contact Plating: Gold
- Current Rating: 6A
- Gender: Male
- Housing Material: PC
- Maximum Contact Resistance: 10mΩ
- Maximum Operating Temperature: +125°C
- Minimum Operating Temperature: -65°C
- Number of Contacts: 21
- Number of Rows: 2
- Pitch: 2.5 mm, 5 mm
- Termination Method: Solder
- Voltage Rating: 250 V