

## DMO - DGO series - High pressure steel - HP reinforced rubber hose



### Technical characteristics

**Technology:** Pipe locked with ratchet stop

**Max operating pressure:** 400 bar

**Temperature:** -40°C to +150°C

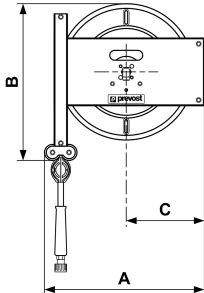
**Equipped with:** Fixed bracket

Inlet: G 3/8 F

Outlet: G 3/8 M and coupling M22 x 1.5 F

Pressure: 400 bar

Temperature: -40°C to +150°C

	A (mm)	B (mm)	C (mm)	ID/OD (mm)	Length (m)	Outlet	Swivel inlet BSPP female thread	Weight (kg)	Parts Numbers
	485	475	237	8 x 15	15	G 3/8 + M22 x 1.5	G 3/8	16	<b>DMO 0815HP</b>
	485	475	237	8 x 15	20	G 3/8 + M22 x 1.5	G 3/8	21	<b>DGO 0820HP</b>