

---

## 7505

Lamps with glass wedge bases for cars



---

### Product benefits

- Wide product range
- Reliable quality

---

### Product features

- Original spare parts

---

Technical data

**Electrical data**


Power input	25 W
Nominal wattage	21.0 W
Nominal voltage	12.0 V
Power input tolerance	±6 %
Test voltage	13.5 V

**Photometrical data**

Luminous flux	460 lm
Luminous flux tolerance	±15 %

**Dimensions & weight**

---

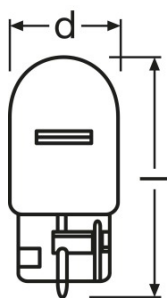

Length	47.5 mm
Diameter	20.0 mm

**Lifespan**

Lifespan B3	400 h
Lifespan Tc	600 h

**Additional product data**

Base (standard designation)	W3x16d
-----------------------------	--------

**Certificates & standards**

ECE category	W21W
--------------	------

**Country specific categorizations**

Order reference	7505 21W 12V W3
-----------------	-----------------

## Product datasheet

---

### Country specific information

Product code	METEL code	SEG-No.	STK-Number	UK Org
4008321090652	OSRA7505	-	-	-

## Product datasheet

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4008321090652	7505	Unpacked 1	40 mm x 20 mm x 20 mm	0.02 dm <sup>3</sup>	9.00 g
4008321090669	7505	Folding carton box 10	51 mm x 54 mm x 145 mm	0.40 dm <sup>3</sup>	90.00 g
4008321090676	7505	Shipping carton box 50	273 mm x 65 mm x 145 mm	2.57 dm <sup>3</sup>	500.00 g
4008321349521	7505	Blister 2	57 mm x 22 mm x 46 mm	0.06 dm <sup>3</sup>	16.00 g
4008321349538	7505	Shipping carton box 20	280 mm x 115 mm x 83 mm	2.67 dm <sup>3</sup>	232.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.