



Equipment for working on pole: insulating ladders and stepladders


Standard extension ladders

2 sections extension ladders, rope and pulley operated

Reference	Folded	Deployed	Numbers of rungs	Weight
MP-607/2-I	4.66 m	8.02 m	2 x 16	30 200
MP-608/2-I	5.22 m	9.14 m	2 x 18	34 400
MP-609/2-I	5.8 m	9.98 m	2 x 20	37 800

3 sections extension ladders, rope and pulley operated

Reference	Folded	Deployed	Numbers of rungs	Weight
MP-607/3-I	2.98 m	6.89 m	3 x 10	24 600
MP-608/3-I	3.82 m	8.86 m	3 x 13	34 600

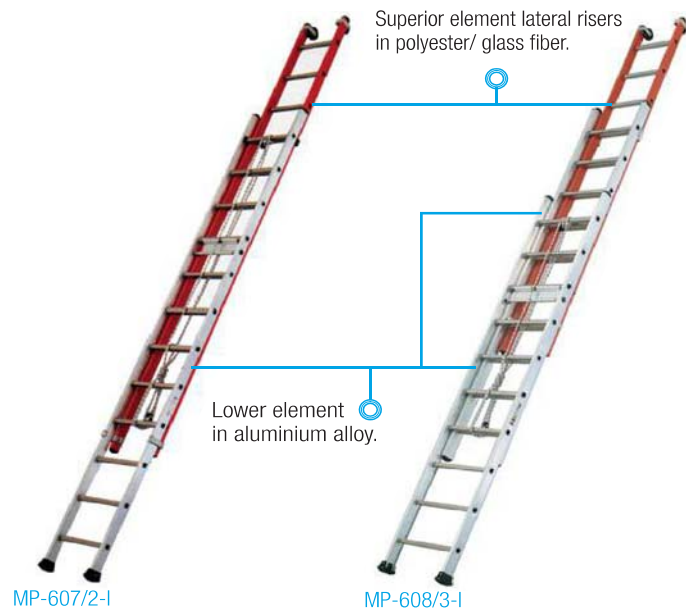

EN 131
CE

Insulating stepladders

Insulation between two steps: 30 000 V

Reference	Nbr steps	Height Access (m)	Height folded (m)	Height based feet (m)	Weight
MP-700-4	3	2.58	1.39	0.68	5 900
MP-700-1	4	2.81	1.64	0.91	6 900
MP-700-2	5	3.04	1.89	1.14	8 000
MP-700-3	6	3.27	2.14	1.37	9 400
MP-700-5	7	3.50	2.39	1.60	11 000



Folding stepladder with railing

Secure non-insulating platform.

Reference	Nbr steps	Height Access	Height folded	Height based feet	Weight
MP-700-6	4	2.88 m	1.40 m	0.88 m	19 500

