




Technical data

51134

One direction thrust ball bearings

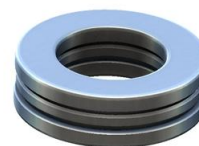

VISUAL (S)

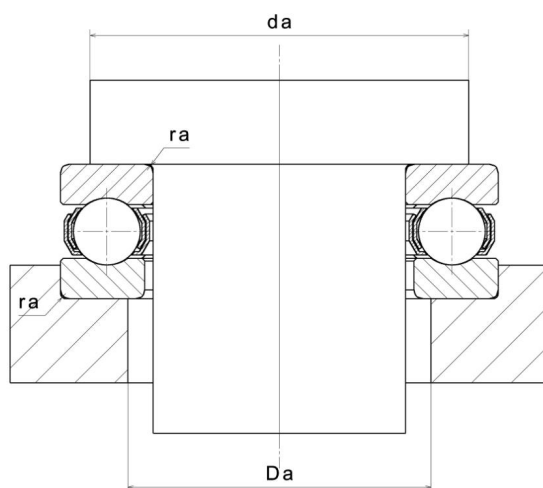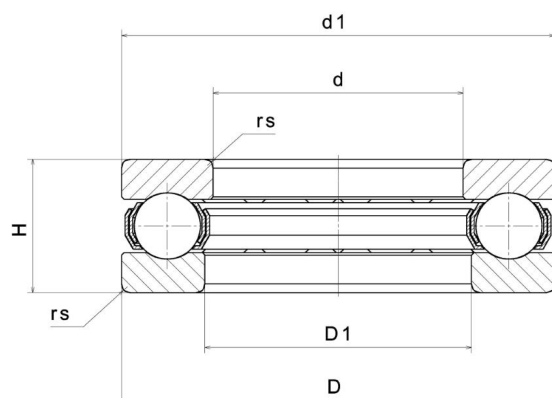

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	170 mm
D - External diameter	215 mm
T - Thrust bearing height	34 mm
rs - Min fillet radius	1,1 mm
Mass	2,77 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	134000000 mN
C0a - Static axial load rating	510000000 mN
Cua - Limit axial load rating	16700000 mN
N lim - Oil lubrication limit speed	9600 °/s
N lim - Grease lubrication limit speed	6600 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	188 mm
da min - Min shoulder diameter IR	197 mm

