

Cable trunking SES® with slots and base punching





GN-A6/4 LF





GN-A6/4 LF








Material: Rigid PVC quality 9051 LF
Colour: grey RAL7030
Operating temperatures: -5 to +65°C
Density: 1,56
Volume resistivity: 10¹⁵ Ω.cm
Dielectric strength: 15kV/mm
Spécification: V0 UL94
 DIN 5510-2 S3, SR1, ST2
Standard length: 2 meters
Double sided adhesive: upon request
Minimum delivery: 1 complete packing (with lids)




| type | trunking art. no. |  m | outside dim. | | cables per trunking (filling 50 %) | | | lids (alone) art. no. |  m | |
|---------|-------------------|---|--------------|------|------------------------------------|---------------------|---------------------|-----------------------|---|----|
| | | | H mm | W mm | 1 mm ² | 1,5 mm ² | 2,5 mm ² | | | |
| GN-A6/4 | 30 x 25 | 0839 0131 013 | 60 | 30 | 25 | 37 | 31 | 26 | 0839 0500 013 | 48 |
| GN-A6/4 | 30 x 40 | 0839 0132 013 | 36 | 30 | 40 | 68 | 56 | 47 | 0839 0510 013 | 24 |
| GN-A6/4 | 40 x 25 | 0839 0141 013 | 48 | 40 | 25 | 52 | 43 | 36 | 0839 0500 013 | 48 |
| GN-A6/4 | 40 x 40 | 0839 0142 013 | 32 | 40 | 40 | 94 | 77 | 64 | 0839 0510 013 | 24 |
| GN-A6/4 | 40 x 60 | 0839 0143 013 | 24 | 40 | 60 | 149 | 122 | 102 | 0839 0520 013 | 24 |
| GN-A6/4 | 40 x 80 | 0839 0144 013 | 24 | 40 | 80 | 204 | 168 | 140 | 0839 0530 013 | 24 |
| GN-A6/4 | 40 x 100 | 0839 0145 013 | 12 | 40 | 100 | 259 | 213 | 178 | 0839 0540 013 | 12 |
| GN-A6/4 | 60 x 25 | 0839 0151 013 | 48 | 60 | 25 | 80 | 66 | 55 | 0839 0500 013 | 48 |
| GN-A6/4 | 60 x 40 | 0839 0152 013 | 32 | 60 | 40 | 144 | 118 | 99 | 0839 0510 013 | 24 |
| GN-A6/4 | 60 x 60 | 0839 0153 013 | 24 | 60 | 60 | 229 | 188 | 157 | 0839 0520 013 | 24 |
| GN-A6/4 | 60 x 80 | 0839 0154 013 | 16 | 60 | 80 | 313 | 257 | 215 | 0839 0530 013 | 24 |
| GN-A6/4 | 60 x 100 | 0839 0155 013 | 16 | 60 | 100 | 398 | 327 | 273 | 0839 0540 013 | 12 |
| GN-A6/4 | 60 x 120 | 0839 0156 013 | 12 | 60 | 120 | 483 | 397 | 332 | 0839 0550 013 | 12 |
| GN-A6/4 | 80 x 25 | 0839 0161 013 | 24 | 80 | 25 | 107 | 88 | 74 | 0839 0500 013 | 48 |
| GN-A6/4 | 80 x 40 | 0839 0162 013 | 24 | 80 | 40 | 193 | 159 | 133 | 0839 0510 013 | 24 |
| GN-A6/4 | 80 x 60 | 0839 0163 013 | 24 | 80 | 60 | 308 | 253 | 211 | 0839 0520 013 | 24 |
| GN-A6/4 | 80 x 80 | 0839 0164 013 | 16 | 80 | 80 | 422 | 347 | 290 | 0839 0530 013 | 24 |
| GN-A6/4 | 80 x 100 | 0839 0165 013 | 12 | 80 | 100 | 537 | 441 | 369 | 0839 0540 013 | 12 |
| GN-A6/4 | 80 x 120 | 0839 0166 013 | 16 | 80 | 120 | 652 | 535 | 447 | 0839 0550 013 | 16 |
| GN-A6/4 | 100 x 40 | 0839 0171 013 | 24 | 100 | 40 | 240 | 198 | 165 | 0839 0510 013 | 24 |
| GN-A6/4 | 100 x 60 | 0839 0172 013 | 16 | 100 | 60 | 384 | 316 | 264 | 0839 0520 013 | 24 |
| GN-A6/4 | 100 x 80 | 0839 0173 013 | 16 | 100 | 80 | 529 | 435 | 363 | 0839 0530 013 | 24 |
| GN-A6/4 | 100 x 100 | 0839 0174 013 | 16 | 100 | 100 | 673 | 553 | 462 | 0839 0540 013 | 12 |

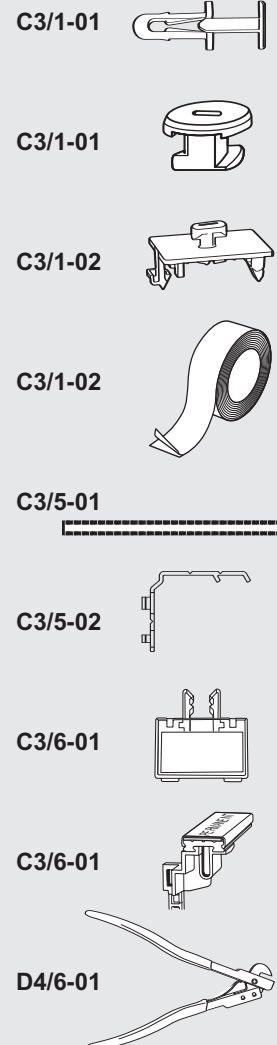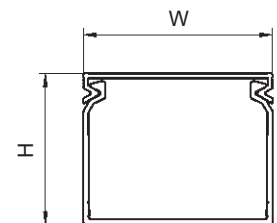


GN-A6/4 LF

 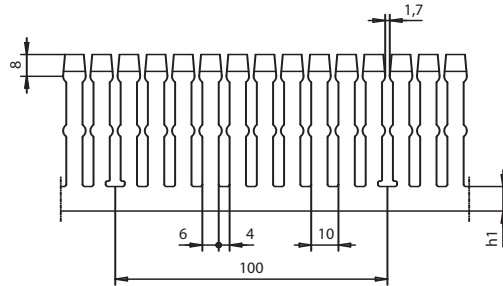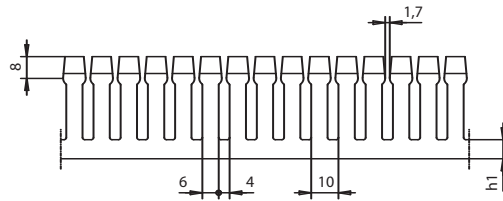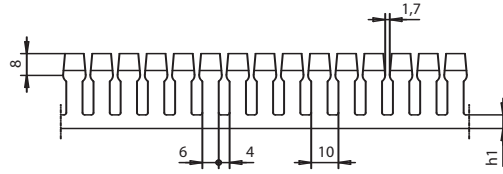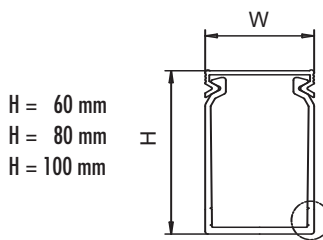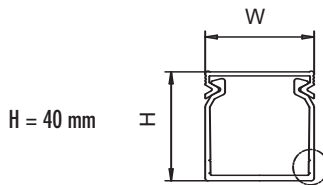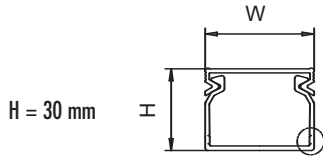

W = 25, 40 and 60 mm

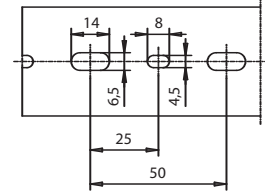

W = 80, 100 and 120 mm

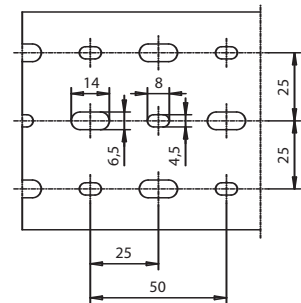

Base punching to NF EN 50085

| | | | | | |
|---------|----|----|----|----|-----|
| H (mm) | 30 | 40 | 60 | 80 | 100 |
| h1 (mm) | 5 | 7 | 9 | 11 | 16 |