


Features

- 50 Ports
- 8P4C
- 1U
- IDC Type

RS PRO 50 Port Telephone Patch Panel

RS Stock No.: 0143846

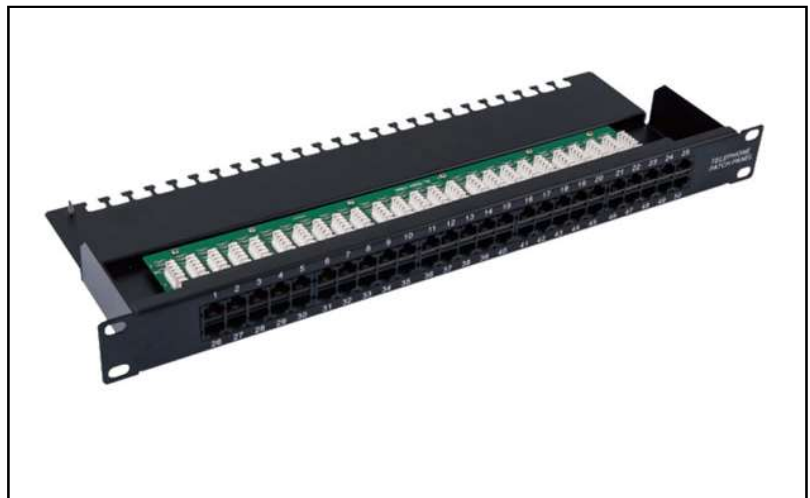

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This is a 1u, 50port rack mountable telephone patch panel. The product is clearly labelled and supports Dual IDC (Krone & 110).

General Specifications

Type	Patch Panel
Category	Cat3 (8P4C)
Number of Ports	50
Shield Type	UTP
Rack Height	1u

Mechanical Specifications

Frame Material	Carbon Steel (SPCC1.6MM)
Frame Finish	Grey Power Coating
Housing Material	PBT
PCB Material	FR-4 Thickness 1.6mm
IDC Material	PC, Phosphor bronze with nickel plating
RJ45 Jack Life	750 Times Min
IDC Life	200 Times Min
Wire	AWG 22-26

Electrical Specifications

Voltage Rating	125 VAC RMS
Current Rating	1.5 AMP
Contact Resistance	100 Milliohms Max
Insulation Resistance	1000 Megohms Min @ 500 VDC
Dielectric Strength	750 VAC RMS 60Hz, 1Min

Approvals

Standards Met

CE UKCA REACH ROHS

