


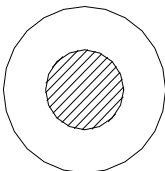

Datasheet

Product Name:	UL1371 26AWG
Product Discription:	UL1371 26AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		Voltage not specified			Conductor		Stranded Sliver plated copper					
Rated Temperature:		105 deg C,60 or 80 deg C Oil, Gasoline Resistant			Size(AWG)		26					
Reference Standard:		UL758			Construction(±0.008mm)		7/0.16					
Cross Section					Stranded Dia.(mm)Ref.		0.48					
					Insulation Material		PTFE					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.15					
					Insulation Dia.(±0.05mm)		0.84					
Marking					Remark:							
No marking on the cable jacket					9033995 Red		9033999 Blue		9034011 Grey		9034015 Violet	
					9033983 Black		9034002 White		9034009 Yellow			
					9033992 Brown		9034005 Green		9034018 Orange			
Applications					Characteristics					Customer Approve		
Internal Wiring, where not subjected to movement or mechanical damage					Test Item			Standard Value			Seal & Stamp	
					Test Material			PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m			1000				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)			127.0(MAX)			Signature: Date:	
Version	Description	Drawn by	Approved by	Date								
0	New document issue	Danniel	Jason	05/10/2015								