



SIVACON, door, right, inspection window, IP55, H: 2000 mm, W: 500 mm, RAL 7035, protection class 1

Model				
product brand name	SIVACON			
product designation	Door			
design of the product	Inspection window			
design of the surface	Powder-coated			
design of the product EMC version	No			
Protection class				
protection class IP	IP55			
operating resource protection class	safety class 1			
Appearance				
RAL color number	7035			
color	light grey			
Product details				
product component				
• ventilation	No			
• viewing door	Yes			
• door for disconnecter lock	No			
Mechanical Design				
height	2 000 mm			
width	500 mm			
opening direction of the door	right			
net weight	16 kg			
material	Steel/glass			
Approvals Certificates				
General Product Approval		Test Certificates	other	
  EG-Konf. 		Special Test Certificate	Confirmation	Miscellaneous
other	Environment			
Miscellaneous		Environmental Confirmations		
Further information				
Information on the packaging				

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1050-2UT14-0BE2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1050-2UT14-0BE2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1050-2UT14-0BE2

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

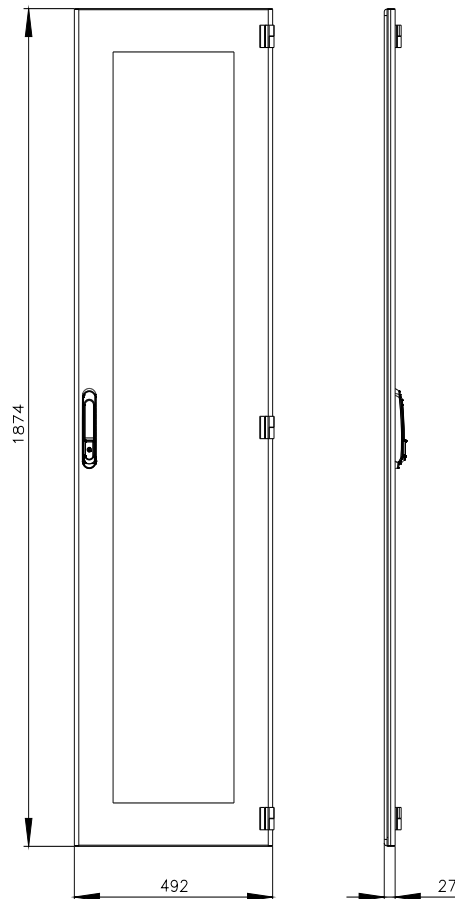

last modified:

4/13/2025 

