




Datasheet

RS PRO AC AXIAL FAN 230VAC 180×180×65mm

Stock number: 175-9783

EN

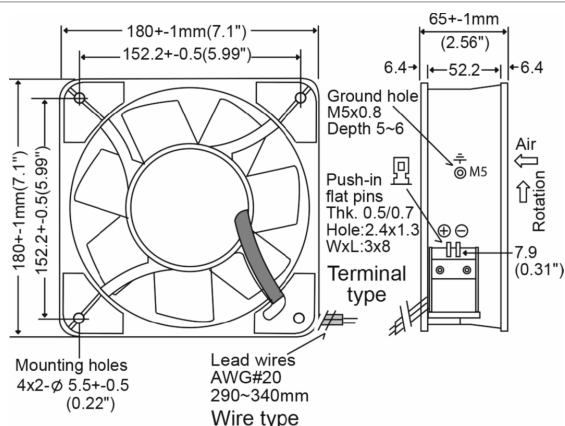

Frame	Diecast Aluminum	Operating Temperature	
Impeller	Metal Alloy	Ball Bearing	
Connection	2x Lead Wires 20 AWG or terminals	-30C ~ +80C (non-condensing)	
Motor	Shaded pole, thermally protected	Storage Temp -40C ~ +100C	
Bearing System	Dual ball bearing	Life Expectancy	
Insulation Resistance	>100M ohm between lead-wire and frame (500VDC)	Ball Bearing	
Dielectric Strength	1 min at 1500 VAC, 50/60Hz	50,000 hours (L10 at 55C)	
		Environmental Protection IP56	Weight:~ 1700g (3.75 lbs)
		m0	

Model Number	1759783
Rated Speed (RPM)	2750
Airflow - CFM	330
Noise Level - (dB)	65
Volts	230
Voltage Range	200~240
Watts	60
Max. Static Pressure	1.52 cm H ₂ O
Curves	5 (50Hz)