
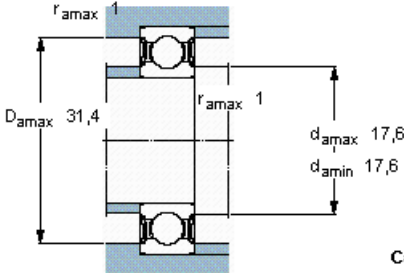


Deep groove ball bearings, single row, seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
12	37	12	10,1	4,15	0,176	-	14000	0,060	6301-2RSH *

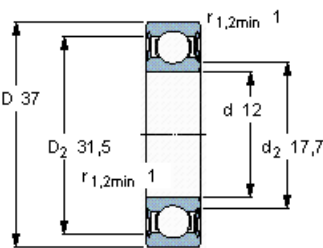

Calculation factors

$k_r = 0,03$
 $f_0 = 11$