


## 8U Desktop Rack - 2-Post Open Frame Rack

Product ID: RK80D

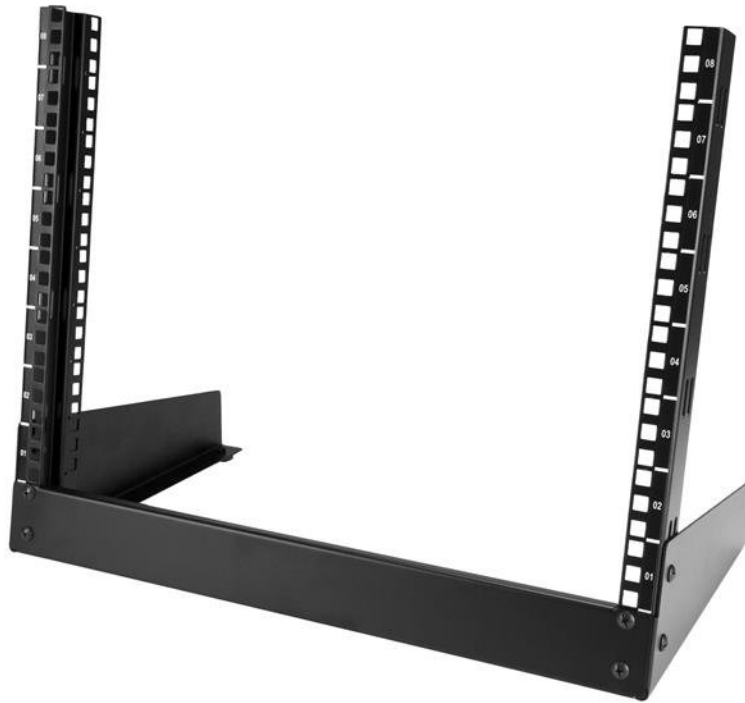

This 2-post desktop rack provides 8U of storage space for mounting smaller A/V and IT equipment.

### **Save money with a low-cost mounting solution**

With this 2-post rack, you can mount equipment at a fraction of the cost of conventional racks. The lightweight rack is engineered to meet EIA-310 rack-mount standards and is constructed of solid steel, ensuring a sturdy and safe mounting solution for your mission-critical equipment.

### **Improve efficiency and accessibility in your office or server room**

The rack features an open frame, free standing design that saves space with a small footprint. It gives you the ability to place rack-mount equipment on any surface in your office, such as your desk. This makes it easy to access your equipment on a daily basis.

### **Hassle-free setup**

The 2-post rack is easy to assemble and includes a pack of 20 M5 screws and cage nuts.

If you're looking for a desktop mounting solution with more rack units, StarTech.com also offers a [12U 2-post desktop rack](#).

The RK80D is backed by a StarTech.com lifetime warranty and free technical support.

### Certifications, Reports and Compatibility



### Applications

- Place KVMs and rack-mount computers or server systems neatly on or beside your desk
- Save space in your SoHo (small office, home office) or server room, by placing equipment on desk or other surface, instead of taking up floor space

### Features

- Save money with a rack-mount solution that's a fraction of the cost of conventional racks
- Improve efficiency in your office or server room by placing equipment on your desk
- Easy setup with hassle-free assembly and mounting hardware included
- Includes 20 M5 screws and cage nuts
- Lightweight design
- EIA-310 compliant

<b>Hardware</b>	Warranty	Lifetime
	Frame Type	Open Frame
	Industry Standards	EIA/ECA-310-E
	Mounting Hole Types	Square (For Cage Nut)
	Mounting Rail Profile	G-Shape
	Rack Type	2-Post
	Special Features	Easy Assembly
		U-Markings
	U Height	8U
Wallmountable	No	
<b>Performance</b>	Weight Capacity	110.5 lb [50 kg]
<b>Physical Characteristics</b>	Color	Black
	Construction Material	Steel
<b>Product Measurements</b>	Product Height	16.1 in [41 cm]
	Product Length	11.5 in [29.2 cm]
	Product Width	19.8 in [50.4 cm]
	Weight of Product	4.8 lb [2.2 kg]
<b>Packaging Information</b>	Flat Pack (Assembly Required)	Yes
	Package Height	3.2 in [81 mm]
	Package Length	21.7 in [55 cm]
	Package Width	4.4 in [11.2 cm]
	Shipping (Package) Weight	5.8 lb [2.6 kg]
<b>What's in the Box</b>	Included in Package	<ul style="list-style-type: none"> <li>1 - Left Base Bracket</li> <li>1 - Right Base Bracket</li> <li>1 - Left Vertical Rail</li> <li>1 - Right Vertical Rail</li> <li>1 - Front Base Bracket</li> <li>4 - Rubber Feet</li> <li>8 - Assembly Screws</li> <li>20 - M5 Screws</li> </ul>

20 - M5 Cage Nuts

1 - Instruction Manual

---

Product appearance and specifications are subject to change without notice.