


Part Number: [0982660061](#)
Status: Active
Overview: [Premo-Flex Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Tin (Sn) Plating, 6 Circuits

Documents:

図面 (PDF)	Datasheet (PDF)
製品仕様書 PS-98266-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
梱包仕様書 PK-98266-001-001 (PDF)	

一般コメント	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
概要	Premo-Flex Cable Jumpers
製品名	Premo-Flex FFC Jumper
UPC	756054766958
機械的性能/材質	
ケーブル長	152.00mm
極数 (実装)	6
材質 - 嵌合部メッキ	錫
Net Weight	0.303/g
梱包形態	ポリ袋
ピッチ - 嵌合部 (インチ)	0.50mm
使用温度範囲	-40° to +105° C
電線サイズ (AWG)	N/A
ケーブル種別	FFC
電気的性能	
最大定格電流	0.5A
最大定格電圧	60V AC
参考情報	
図面・仕様書情報	
梱包仕様書	PK-98266-001-001
製品仕様書	PS-98266-001-001
製品図面	SD-98266-001

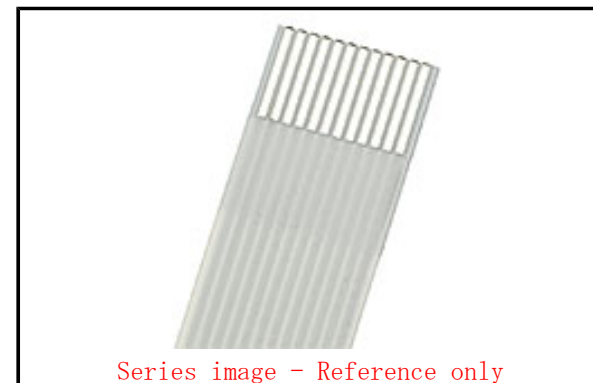

EU ELV	Not Relevant
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ECHA_01_2020 (16	
January 2020	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit	
Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[98266 Series](#)

Mates With
 Easy-On FFC/FPC Connector:

[527450633](#) , [527460633](#) , [525590633](#)