




147-37

**37 mm Open End Insert for 14 mm
x 18 mm Rectangular Connector
Wrench**



PRODUCT DETAILS

- Insert is fixed to the torque wrench by a spring-loaded retractable pin
- Range covers from 9x12 to 27x36 receivers, from 7 to 90 mm openings, from 9 to 3,000 N·m
- Sizes with * in torque length require a target torque setting calculation
- Suitable for 7465, 74W9, 74W14, 74P9, 74P14, IZO-D, TAW9, TAW14, TAW24, TAWM9, TAWM14, TAWM24 wrenches

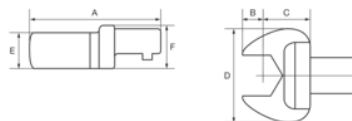

Follow the Fish!



PRODUCT ATTRIBUTES

Product				A	B	C	D	E	F	
147-37	37 mm	14x18 mm	360 N·m	80 mm	7 mm	50* mm	84 mm	14 mm	20 mm	290 g

Follow the Fish!



Contact: info@bahco.com / www.bahco.com