


drylin® T guide carriage TW-01
TW-01-30

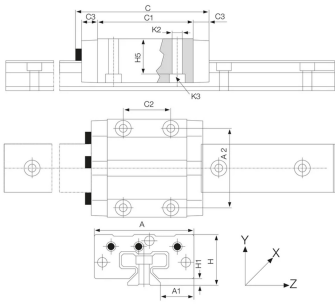

drylin® T guide carriage TW-01

- drylin® T linear carriage of the standard 01 series
- With individual clearance adjustment
- Long service life due to iglidur® J
- Optionally configurable as floating bearing version in y or z direction
- Material: aluminium housing, plastic lid, iglidur® J slider

Product description

Introducing the drylin T guide carriage TW-01, a reliable choice for your linear motion needs. This standard carriage features individual clearance adjustment for precise control and boasts a long service life thanks to its durable iglidur J material. With an aluminium housing and a plastic lid, it combines strength and lightweight design. Additionally, it can be configured as a floating bearing version in the y or z direction, making it versatile for various applications. Upgrade your projects with the drylin T carriage TW-01 today!

Manufacturing and installation tolerances

H-tolerance	±0,35 mm
-------------	----------

Mechanical properties

Static load capacity Coy	14000 N
--------------------------	---------



Dimensions

H	42 mm
A	90 mm
C	109 mm
A1	31 mm
A2	72 mm
C1	79 mm
C2	52 mm
C3	12 mm
H1	6.5 mm
H5	27 mm
Thread K2	M10
Thread K3	M8

General properties

Sliding element material	iglidur® J
size	01-30
Floating bearing	none

Certificates and standards

