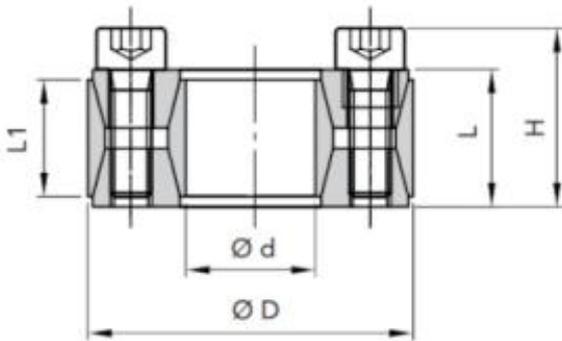


06400035

RCK 40 - Not self centering

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06400035
$\varnothing d$ (DD) mm	35
$\varnothing D$ (D) mm	60
L1 (L1) mm	17
L (L) mm	20
H (H) mm	28
Maximum torque Mt (MT) Nm	700
Clamping pressure - Shaft (CPS) N/mm ²	180
Clamping pressure - Hub (CPH) N/mm ²	105
Clamping screws DIN 912 MAT. 12.9 - N. (CSN)	12
Clamping screws DIN 912 MAT. 12.9 - Type (CSTY)	M6x18
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTO) Nm	14
Extraction thread - Type (ETT)	M8
Extraction thread - N. (ETN)	4
Weight (WEIGHT) kg	0.32